


 
NUMBER 2030578	PART NUMBER	REV	A	OPERATING DISTANCE	SWITCH	OUTPUT	RoHS COMPLIANT	MFR PART NO
	2030578-1	D	45	1.5	NORMALLY OPEN	PNP	NO	DCC 08 M 1.5 PSK-TSL
	2030578-2	D	29	1.5	NORMALLY OPEN	PNP	NO	DCCK 08 M 1.5 PSK-TSL
	2030578-3	D	29	1.5	NORMALLY CLOSED	PNP	NO	DCCK 08 M 1.5 POK-TSL
	2030578-4	D	29	1.5	NORMALLY CLOSED	NPN	NO	DCCK 08 M 1.5 NOK-TSL
	2030578-5	D	29	1.5	NORMALLY OPEN	NPN	NO	DCCK 08 M 1.5 NSK-TSL
	2030578-6	D	45	2.0	NORMALLY OPEN	PNP	YES	DCC 08 M 02 PSK-TSL

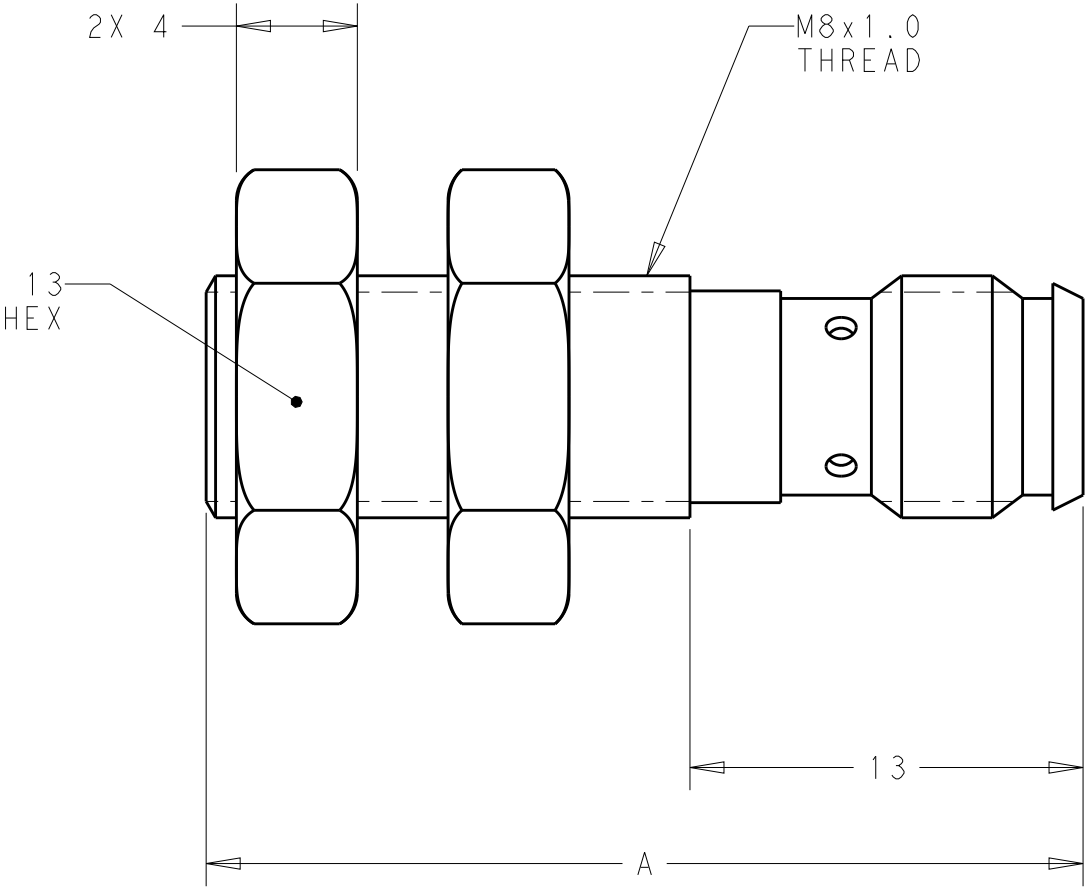

1. MANUFACTURER/VENDOR PART NUMBER:
SEE TABLE
2. MANUFACTURER/VENDOR:
di-soric GmbH & Company KG
www.di-soric.com
3. DIMENSIONS/TOLERANCES:
ALL DIMENSIONS ARE NOMINAL
UNLESS OTHERWISE SPECIFIED.
4. COMPLIANCE:
SEE TABLE
5. REQUIRED CHARACTERISTICS/PERFORMANCE:
SEE TABLE
6. ALTERNATE PART NUMBER AND
MANUFACTURER/VENDOR:
NONE

APPLICATION TOOLING COMMERCIALLY
PURCHASED PRODUCT SPECIFICATION

D	ECR-17-008839	13JUN2017	DJG	-
LTR	REVISION RECORD	DATE	DWN	APVD

DIMENSIONS: mm	MATERIAL SS HOUSING	FINISH -		
	 TE Connectivity			
TITLE SENSOR, PROXIMITY SWITCH, INDUCTIVE, THREADED CONNECTION, WITH LEDS				
SIZE A3	NUMBER 2030578		SHEET 1 OF 1	REV D

THIS INFORMATION IS CONFIDENTIAL AND PROPRIETARY TO TYCO ELECTRONICS CORPORATION AND ITS WORLDWIDE SUBSIDIARIES AND AFFILIATES (TE). IT MAY NOT BE DISCLOSED TO ANYONE, OTHER THAN TE PERSONNEL, WITHOUT AUTHORIZATION FROM TE (www.te.com).