




- Home
- Products
- Online Catalog
- Request Quote
- Order Online
- Check Stock
- Request Print Catalog
- Request Samples
- Engineering Data
- Distributors
- Capabilities Brochure

CALL NOW:  
203 888-2133



Home > 3/8 Hex Male-Female Standoffs

3/8 HEX MALE-FEMALE STANDOFFS

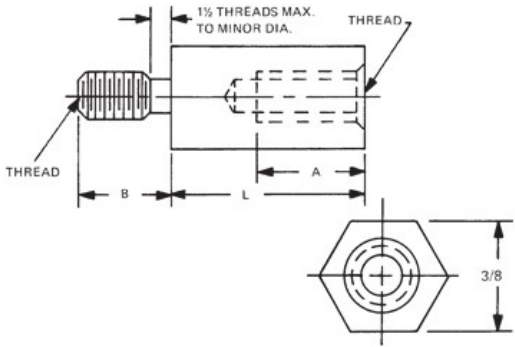

Qty1 \*

Qty2

Qty3

|                                  |      |       |
|----------------------------------|------|-------|
| <input type="radio"/>            | 4648 | 2"    |
| <input type="radio"/>            | 4649 | 2-1/8 |
| <input type="radio"/>            | 4650 | 2-1/4 |
| <input type="radio"/>            | 4651 | 2-3/8 |
| <input checked="" type="radio"/> | 4652 | 2-1/2 |
| <input type="radio"/>            | 4653 | 2-5/8 |
| <input type="radio"/>            | 4654 | 2-3/4 |
| <input type="radio"/>            | 4655 | 2-7/8 |
| <input type="radio"/>            | 4656 | 3"    |
| <input type="radio"/>            | 4657 | 3-1/4 |
| <input type="radio"/>            | 4658 | 3-1/2 |
| <input type="radio"/>            | 4659 | 3-3/4 |
| <input type="radio"/>            | 4660 | 4"    |

Thread \*

| Select                           | Code | Thread |
|----------------------------------|------|--------|
| <input type="radio"/>            | 1224 | 12-24  |
| <input type="radio"/>            | 440  | 4-40   |
| <input type="radio"/>            | 632  | 6-32   |
| <input type="radio"/>            | 832  | 8-32   |
| <input checked="" type="radio"/> | 1032 | 10-32  |

Thread Length Code

| Thread | A    | B    |
|--------|------|------|
| 4-40   | 1/4  | 3/16 |
| 6-32   | 3/8  | 1/4  |
| 8-32   | 7/16 | 3/8  |
| 10-32  | 1/2  | 3/8  |
| 12-24  | 1/2  | 3/8  |

Material \*

| Select                           | Code | Material        | RoHS |
|----------------------------------|------|-----------------|------|
| <input type="radio"/>            | AL   | Aluminum        | YES  |
| <input type="radio"/>            | B    | Brass           | YES  |
| <input checked="" type="radio"/> | SS   | Stainless Steel | YES  |
| <input type="radio"/>            | S    | Steel           | YES  |
| <input type="radio"/>            | N    | Nylon           | YES  |

[Home](#) [Previous](#) [Next](#)  
[Related Metric](#)

Ordering Code

|        |        |          |        |
|--------|--------|----------|--------|
| xxxxx  | xxxx   | xx       | x      |
|        |        |          |        |
| Length | Thread | Material | Finish |

PART: 4652 1032 SS

Red ?'s show missing selections. [Help](#)

[Material Specifications](#)  
[Ordering non-standard items](#)  
[Download a Drawing](#)

Add to Cart

Finish \*

|                                  |                                  |
|----------------------------------|----------------------------------|
| <input checked="" type="radio"/> | Plain Finish                     |
| <input type="radio"/>            | 1-Cad clear chromate/commercial* |
| <input type="radio"/>            | 2-Cad clear chromate*            |
| <input type="radio"/>            | 3-Cad yellow chromate*           |
| <input type="radio"/>            | 4-Chrome over nickel             |
| <input type="radio"/>            | 5-Nickel                         |
| <input type="radio"/>            | 6-Gold iridite                   |
| <input type="radio"/>            | 7-Clear iridite                  |
| <input type="radio"/>            | 9-Alodine 1200*                  |
| <input type="radio"/>            | 10-Bright chrome                 |
| <input type="radio"/>            | 11-Satin chrome                  |
| <input type="radio"/>            | 12-Zinc                          |