
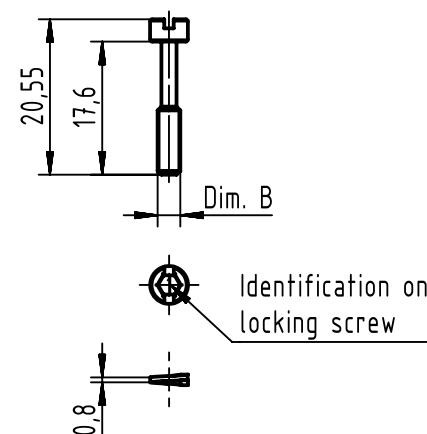
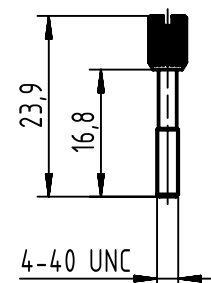
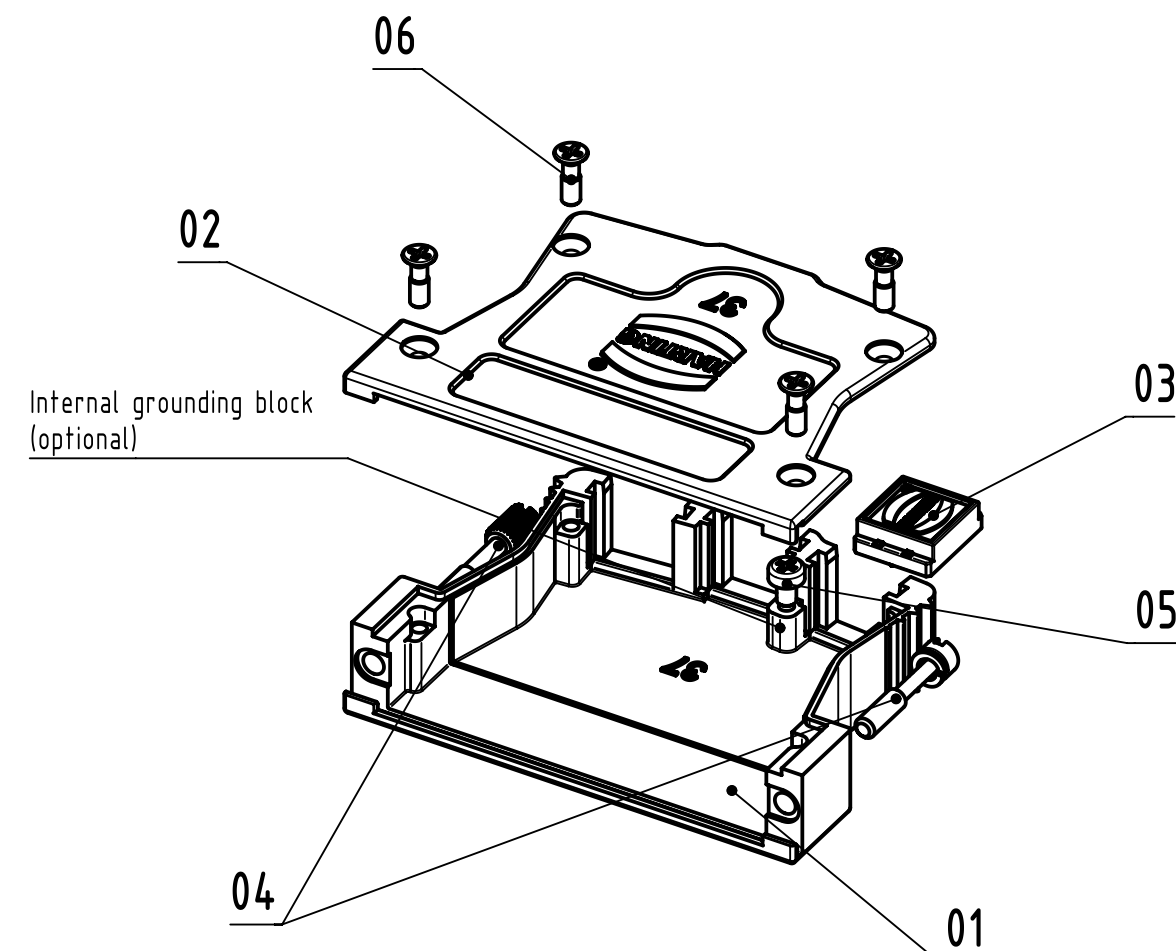


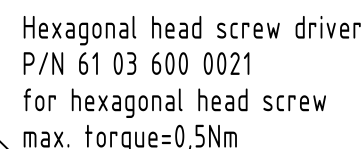

1 For strain relief an additional InduCom cable clamp or a crimp flange and ferrule combination depending on the cable is necessary

	All Dimensions in mm Original Size DIN A3		Scale 1:1		Free size tol.		Ref.		
							Sub.		
	All rights reserved		Created by ZENGDO		Inspected by LUOK		Standardisation HOFFMANN		
	Department EC PD - CN						Date 2018-03-08		
HARTING Electronics GmbH D-32339 Espelkamp		Title InduCom size 4 (37-pole) easy access hood assembly						Doc-Key / ECM-Nr. 100522752/UGD/000/E 500000132046	
		Type TB		Number 6103001X118				Rev. E	
								Pag 1/-	

6103 001 X118 YYY				
6103 001 0118	4-40 UNC	Knurled thumb screw	Without ring	With internal grounding block
6103 001 1118	M3	Hexagonal screw with captive washer	1	
6103 001 2118	4-40 UNC	Hexagonal screw with captive washer	3	
6103 001 3118	M3	Knurled thumb screw	With ring	
6103 001 0118 010	4-40 UNC	Knurled thumb screw	Without ring	Without internal grounding block
6103 001 1118 010	M3	Hexagonal screw with captive washer	1	
6103 001 2118 010	4-40 UNC	Hexagonal screw with captive washer	3	
6103 001 3118 010	M3	Knurled thumb screw	With ring	
Part Number	Dim. B screw size	Screw type	Identification for locking screw	Internal grounding block