


NanoCOM-SKU

COM Express Type 10 with 6th Gen Intel® Core™/Celeron® Processor 3000 Series Processors

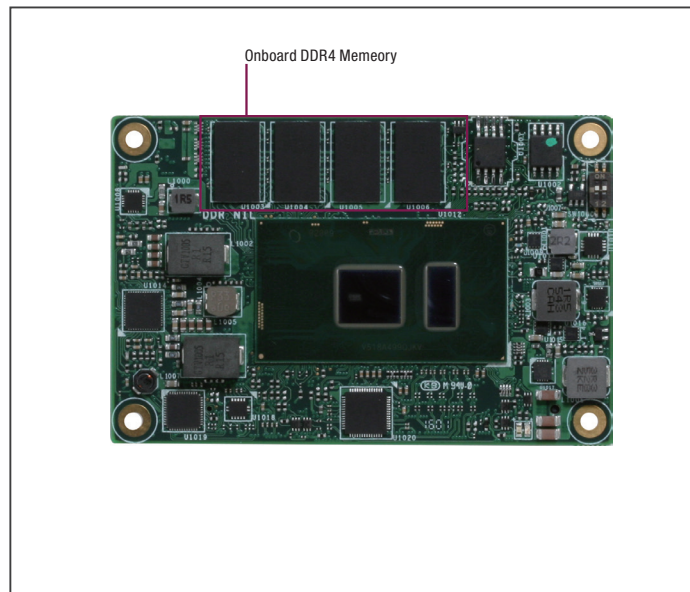

Features

- Onboard LPDDR4, up to 4GB
- LVDS x 1, DDI x 1
- USB 2.0 x 8, USB 3.2 Gen 1 x 2
- PCIe [x1] x 4
- Intel® I219-LM GbE x 1
- COM Express Type 10, 3.31" x 2.17" (84mm x 55mm)



Specifications

System	
Form Factor	COM Express Mini Size, Type 10
CPU	6th Generation Intel® Core™ Processors: Intel® Core™ i7-6600U (2C/4T, 2.60 GHz, 15W) Intel® Core™ i5-6300U (2C/4T, 2.40 GHz, 15W) Intel® Core™ i3-6100U (2C/4T, 2.30 GHz, 15W) Intel® Celeron® Processor 3000 Series: Intel® Celeron® Processor 3955U (2C/2T, 2.00 GHz, 15W)
Chipset	Integrated with Intel® SoC
Memory	Onboard LPDDR4 2133MHz, up to 8GB
Onboard Storage	—
BIOS	AMI UEFI
Wake on LAN	Yes
Watchdog Timer	255 Levels
Dimension	3.31" x 2.17" (84mm x 55mm)
Security	fTPM
Power	
Power Requirement	+12V and +5VSB for ATX, +12V for AT
Power Type	AT/ATX
Power Consumption (Typical)	Intel® Core™ i7-6600U, 1.52A @+12V
Display	
Graphics Controller	Intel® HD Graphics 510 Intel® HD Graphics 520
Video Output	Dual Display: DDI x 1, up to 2560 x 1440 18/24-bit Single-Channel LVDS/eDP x 1, up to 2560 x 1440"
I/O	
Ethernet	Intel® I219-LM GbE x 1
Audio	High Definition Audio Interface
USB Port	USB 2.0 x 8, USB 3.2 Gen 1 x 2
Serial Port	2-Wire UART x 2 (Tx/Rx)
HDD Interface	SATA III x 2

Expansion	PCIe 3.0 [x1] x 4 LPC x 1
GPIO	8-bit
SMBus/I2C	I2C x 1, SMBus x 1
Environment	
Operating Temperature	32°F ~ 140°F (0°C ~ 60°C) Optional: -40°F ~ 185°F (-40°C ~ 85°C)
Storage Temperature	-40°F ~ 185°F (-40°C ~ 85°C)
Operating Humidity	0% ~ 90% relative humidity, non-condensing
EMC	CE/FCC Class A
OS Support	Windows® 10 (64-bit) Linux Ubuntu 16.04.2/Kernel 4.8.0
Weight	0.15 lb. (0.07Kg)

Packing List


- NanoCOM-SKU

Optional Accessories

Part Number	Description
ECB-920A-A11-0001	COMe Type 6/10 Carrier Board. ATX. 2.5GbE. 8USB. 2COM. 4SATA. PCIe. AT/ATX. Rev. A1.1
NanoCOM-SKU-HSP01	Heat Spreader. 84 x 55 x 11 mm. Black.
NanoCOM-FAN02	Cooler. 84 x 53 x 22.2mm. Use w/HSP


Block Diagram

Unit: mm

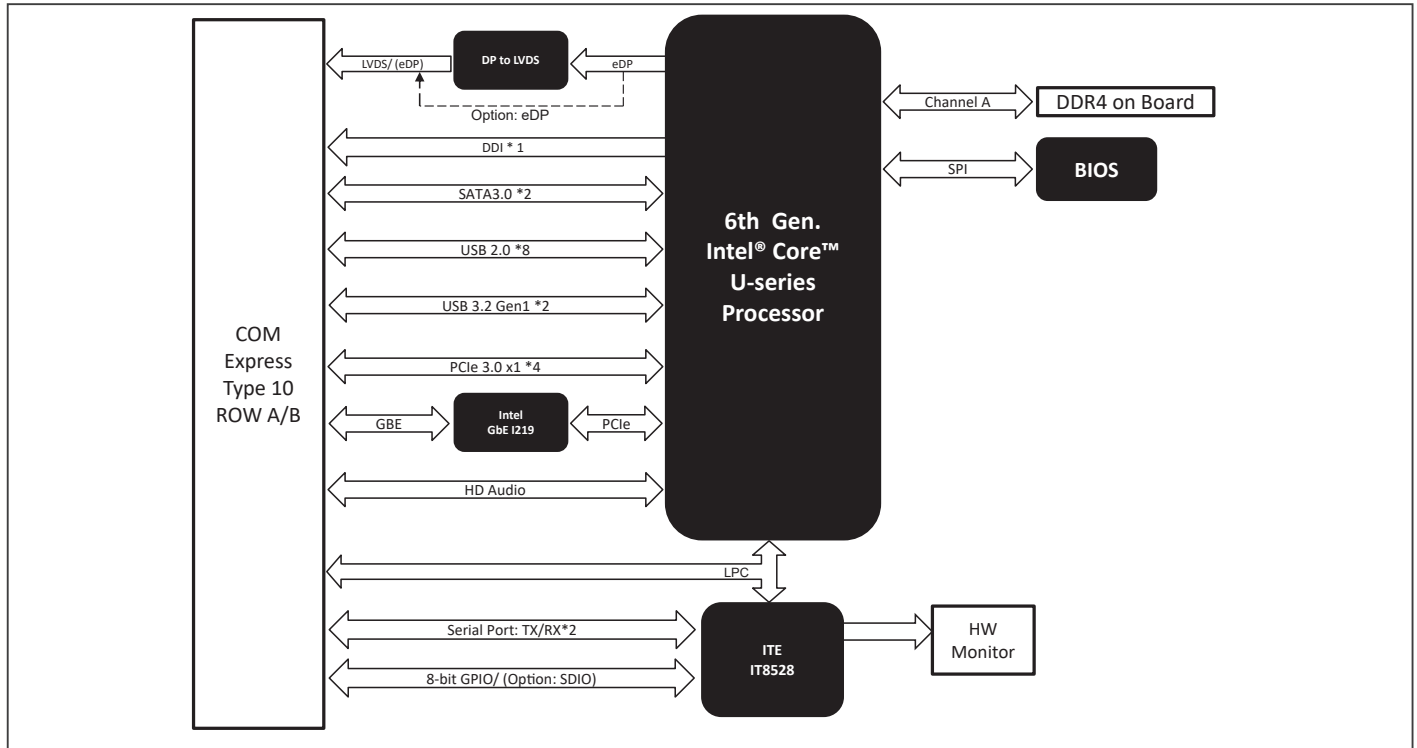

Dimension

Unit: mm

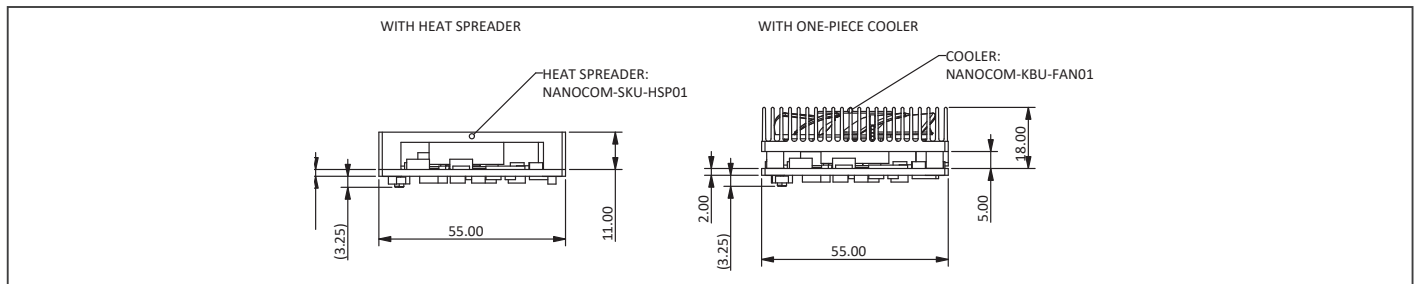

Ordering Information

Part Number	COM Express Type	CPU	Memory	ECC support	Display	Storage	LAN	USB	UART	Expansion	Power	Temperature	Others
NANOCOM-SKU-A10-0001	Type 10	Intel® Core™ i7-6600U	4GB Onboard DDR4	—	LVDS x 1, DDI x 1	SATA III x 2	Intel® I219-LM x 1	USB 3.2 Gen 1 x 2 USB 2.0 x 8	2-Wire UART x 2 (Tx/Rx)	PCIe 3.0 [x1] x 4	12V	0°C ~ 60°C	LPC, GPIO 8-bit, I2C, SMBus
NANOCOM-SKU-A10-0002	Type 10	Intel® Core™ i5-6300U	4GB Onboard DDR4	—	LVDS x 1, DDI x 1	SATA III x 2	Intel® I219-LM x 1	USB 3.2 Gen 1 x 2 USB 2.0 x 8	2-Wire UART x 2 (Tx/Rx)	PCIe 3.0 [x1] x 4	12V	0°C ~ 60°C	LPC, GPIO 8-bit, I2C, SMBus
NANOCOM-SKU-A10-0003	Type 10	Intel® Core™ i3-6100U	4GB Onboard DDR4	—	LVDS x 1, DDI x 1	SATA III x 2	Intel® I219-LM x 1	USB 3.2 Gen 1 x 2 USB 2.0 x 8	2-Wire UART x 2 (Tx/Rx)	PCIe 3.0 [x1] x 4	12V	0°C ~ 60°C	LPC, GPIO 8-bit, I2C, SMBus