

# WS2812B LED Breakout Board

SKU 104990139

- Integrating control circuit and RGB chip
- Built-in signal reshaping circuit
- Built-in electric rest circuit and power lost reset circuit
- 256 brightness and 16777216 color display

IN STOCK 4 Available

Qty: 

-

1

+

ADD TO CART

## Description

WS2812 is an intelligent control LED light source that the control circuit and RGB chip are integrated in a package of 5050 components. It includes intelligent digital port data latch and signal reshaping amplification drive circuit. Also include a precision internal oscillator and a 12V voltage programmable constant current control part, effectively ensuring the pixel point light color height consistent.

LED with low driving voltage, environmental protection and energy saving, high brightness, scattering angle is large, good consistency, low power, long life and other advantages. The control chip integrated in LED above becoming more simple circuit, small volume, and convenient installation.

This is a breakout board of WS2812B. If you want a 6 pins WS2812 RGB LED, look at here.

## Features

- Integrating control circuit and RGB chip
- Built-in signal reshaping circuit
- Built-in electric rest circuit and power lost reset circuit
- 256 brightness and 16777216 color display
- Cascading port transmission signal
- Breakout board

## Specification

- Power Supply Voltage: +3.5~+5.3V

See More


## Recipes



Iron Man 4th Generation Arc Reactor



DeskPomo

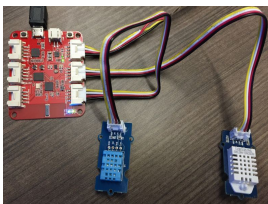

Arduino Calendar / Dashboard

## Questions and Answers

Have a question about this? Ask people who own it.

Downloaded from [Arrow.com](#)

## Recommendations



WS2812B RGB LED with Integrated...



Digital RGB LED Flexi-Strip 60 LED -...



 
8x32 RGB LED Matrix w& WS2812B -...



10 Segment LED - White



Mini vibration motor 2.0mm



3mm LED Blue - 25 PCs



 
Europe Standard USB Wall Power Supply...




Mini vibration motor



Breadboard Jumper Wire Set (140 PCs...



Seeed Micro BLE Module w&...

 

Grove - Moisture Sensor



Power converter 6 in 1 pack

0

Just to be sure, these come by pack of 5 ? Or is it the price for one single breakout ?

Etienne Landon on Oct 19,2016


Hi Etienne, thanks for reaching us. The price above is for one breakout only.

Law Yan on Oct 28,2016 15:06 PM

Reply | upvote (0)


Reply | upvote (0)

View History




Flexible LED Strip - RGB

ADD TO CART




EL Wire-Blue 3m

ADD TO CART




EL Tape - Red 1m

ADD TO CART



EL Tape - White 1m

ADD TO CART



EL Tape - Yellow 1m

ADD TO CART

POPULAR SEARCHES

PCB Manufacturing

PCB Stencil

Arduino

XBee

Arduino Shield

Beaglebone Black

Raspberry Pi

Raspberry Pi Touchscreen

Linkit

Cubieboard

Beaglebone Cape

FPGA

LinkIt ONE

Crazyflie 2.0

Raspberry Pi 3 Model B

RF Explorer

DSO Nano v3


MediaTek X20


HiKey Board


rplidar

raspberry pi relay

RPLIDAR A2

 SHIPPING INFORMATION

 KNOWLEDGE BASE

 HELP CENTER

Seed Info

Reach Us

Distributors

Designers

Careers

Site Map

Customer Service

Contact Us

Customer Support

Technical Support

Terms and Conditions

Order Information

Shipping Information

Payment Information

Warranty and Return


Terms of use


Privacy Policy


Stay Tuned


Subscribe to get the latest product releases, activities and tutorials from Sseed Studio.


>













Copyright © 2008-2017 Sseed Development Limited All rights reserved


PayPal

VISA





Select Language ▼

 Contact Support



Grove - Universal 4 Pin Buckled 5cm...



Conductive Stainless Steel Sewing...



Digital RGB LED Flexi-Strip 30 LED -...



DSO Nano v3



Xadow - RGB OLED 96x64



Grove - Water Sensor



3W Solar Panel 138X160



12mm Domed Push Button Pack