



Fittings with fixed external thread

HG-S Straight fitting, IP66


Straight external thread.

Features and benefits

- One piece, fast fit
- High pull-off strength
- Highly resistant to solvents and oils
- Free of halogen, sulphur and phosphorus
- Metric threads supplied with locknuts



For other fittings please check our website.

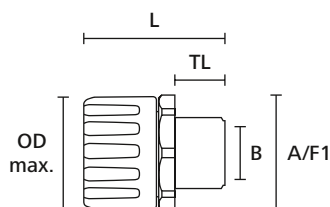

HelaGuard fitting, straight with fixed external thread



HelaGuard HG-S Straight, IP66.


MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-50 °C to +135 °C
Flammability	UL 94 V2



TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	A/F Body (A/F1)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG10-S-M12	10	M12	7.5	19	33	19	9	10 pcs.	Black (BK)	166-21000
HG10-S-M16	10	M16	9.5	19	35	19	11	10 pcs.	Black (BK)	166-21020
HG10-S-PG7	10	PG7	7.5	19	33	19	9	10 pcs.	Black (BK)	166-21010
HG10-S-PG9	10	PG9	9.5	19	35	19	11	10 pcs.	Black (BK)	166-21031
HG11-S-M12	11	M12	7.5	19	33	19	9	10 pcs.	Black (BK)	166-21021
HG11-S-PG7	11	PG7	7.5	19	33	19	9	10 pcs.	Black (BK)	166-21032
HG13-S-M12	13	M12	7.5	24	35	23	9	10 pcs.	Black (BK)	166-21022
HG13-S-M16	13	M16	11.0	24	37	23	11	10 pcs.	Black (BK)	166-21001
HG13-S-M20	13	M20	12.5	24	40	23	14	10 pcs.	Black (BK)	166-21023
HG13-S-PG7	13	PG7	7.5	24	35	23	9	10 pcs.	Black (BK)	166-21033
HG13-S-PG9	13	PG9	11.0	24	37	23	11	10 pcs.	Black (BK)	166-21011
HG13-S-PG11	13	PG11	12.5	24	36	23	10	10 pcs.	Black (BK)	166-21034
HG16-S-M16	16	M16	11.0	29	41	28	11	10 pcs.	Black (BK)	166-21002
HG16-S-M20	16	M20	14.5	29	34	28	14	10 pcs.	Black (BK)	166-21003
HG16-S-PG9	16	PG9	11.0	29	41	28	11	10 pcs.	Black (BK)	166-21035


All dimensions in mm. Subject to technical changes.

 Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.



Fittings with fixed external thread

HG-S Straight fitting, IP66

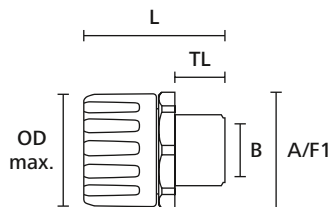

HelaGuard fitting, straight with fixed external thread

TYPE	Nominal Ø	Thread Size	Min. Bore Size (B)	Outside Ø max (OD max.)	Length (L)	A/F Body (A/F1)	Thread Length (TL)	Pack Cont.	Colour	Article-No.
HG16-S-PG11	16	PG11	14.5	29	40	28	10	10 pcs.	Black (BK)	166-21012
HG16-S-PG13	16	PG13,5	14.5	29	40	28	10	10 pcs.	Black (BK)	166-21013
HG16-S-PG16	16	PG16	14.5	29	41	28	11	10 pcs.	Black (BK)	166-21036
HG20-S-M20	20	M20	14.5	32	44	30	14	10 pcs.	Black (BK)	166-21025
HG21-S-M20	21	M20	14.5	32	44	30	14	10 pcs.	Black (BK)	166-21004
HG21-S-PG13	21	PG13,5	16.5	32	40	30	10	10 pcs.	Black (BK)	166-21039
HG21-S-PG16	21	PG16	18.0	32	41	30	11	10 pcs.	Black (BK)	166-21014
HG21-S-PG21	21	PG21	20.5	32	42	30	12	10 pcs.	Black (BK)	166-21040
HG25-S-M25	25	M25	19.5	39	49	37	15	10 pcs.	Black (BK)	166-21026
HG28-S-M25	28	M25	19.5	44	49	42	15	10 pcs.	Black (BK)	166-21005
HG28-S-M32	28	M32	26.5	44	50	42	16	10 pcs.	Black (BK)	166-21027
HG28-S-PG21	28	PG21	22.5	44	46	42	12	10 pcs.	Black (BK)	166-21015
HG28-S-PG29	28	PG29	27.5	44	46	42	12	10 pcs.	Black (BK)	166-21041
HG34-S-M32	34	M32	26.5	51	53	49	16	10 pcs.	Black (BK)	166-21006
HG34-S-M40	34	M40	32.5	51	53	49	16	10 pcs.	Black (BK)	166-21028
HG34-S-PG29	34	PG29	30.5	51	49	49	12	10 pcs.	Black (BK)	166-21016
HG42-S-M40	42	M40	32.5	63	60	60	16	2 pcs.	Black (BK)	166-21007
HG42-S-M50	42	M50	40.5	63	60	60	16	2 pcs.	Black (BK)	166-21029
HG42-S-PG36	42	PG36	40.0	63	56	60	12	2 pcs.	Black (BK)	166-21017
HG54-S-M50	54	M50	42.0	76	65	73	16	2 pcs.	Black (BK)	166-21008
HG54-S-M63	54	M63	53.0	76	65	73	16	2 pcs.	Black (BK)	166-21030
HG54-S-PG42	54	PG42	47.0	76	61	73	12	2 pcs.	Black (BK)	166-21042
HG54-S-PG48	54	PG48	52.0	76	61	73	12	2 pcs.	Black (BK)	166-21018
HG67-S-M63	67	M63	56.0	90	70	87	16	1 pc.	Black (BK)	166-21009
HG67-S-PG48	67	PG48	52.0	90	66	87	12	1 pc.	Black (BK)	166-21019

All dimensions in mm. Subject to technical changes.

Colour grey available on request. Minimum Order Quantity (MOQ) may differ from package content.