


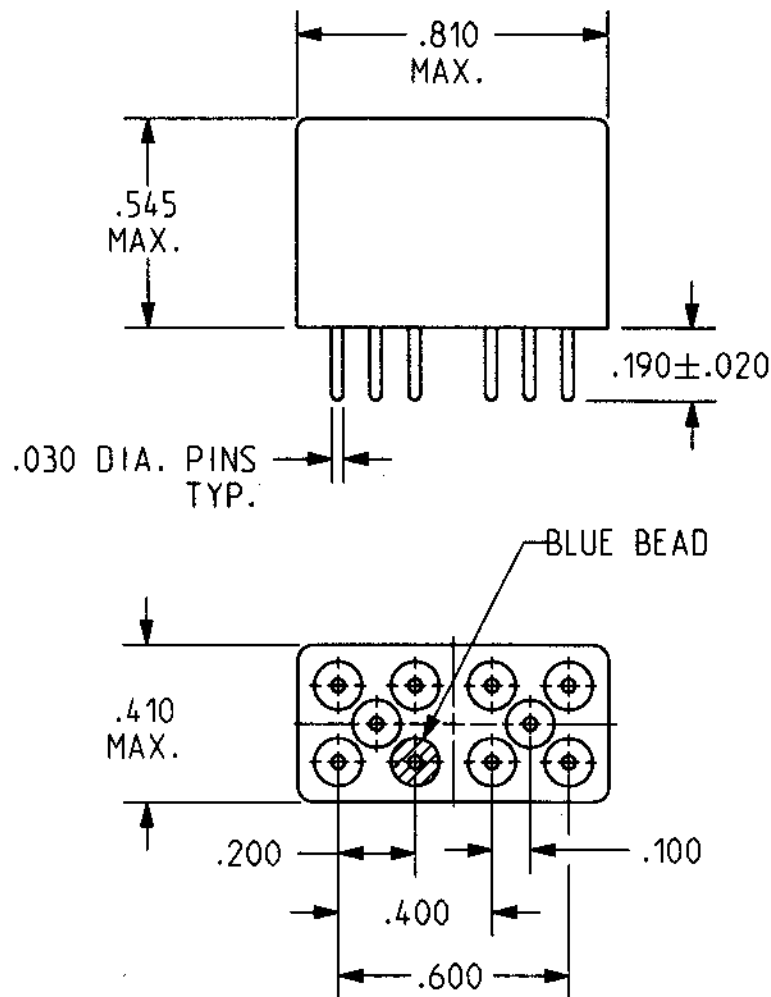

REV. 0
DCO 64175

COIL: @ ~~25°C~~ 20°C

SET	RESET
500 OHMS ±10% @ 25°C	500 OHMS ±10% @ 25°C
24 VDC NOMINAL VOLTAGE	24 VDC NOMINAL VOLTAGE
12 VDC MUST OPERATE	12 VDC MUST OPERATE

ENVIRONMENT:


VIBRATION 55 Hz 3000 Hz 30 g's

SHOCK 150 g's 11 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: SET & RESET TIME 4 MS MAX.
BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

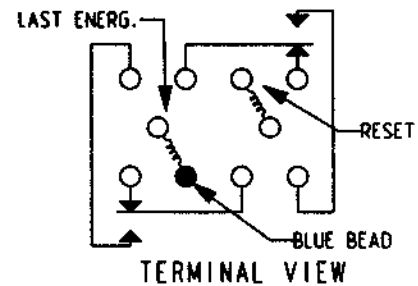

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 11/9/01

CK. 1/2/01

CII Technologies
advanced control electronic solutions

CUST. C.I.I. STD.

CUST. NO.

TYPE 3SDM RELAY

3SDM5004H1