


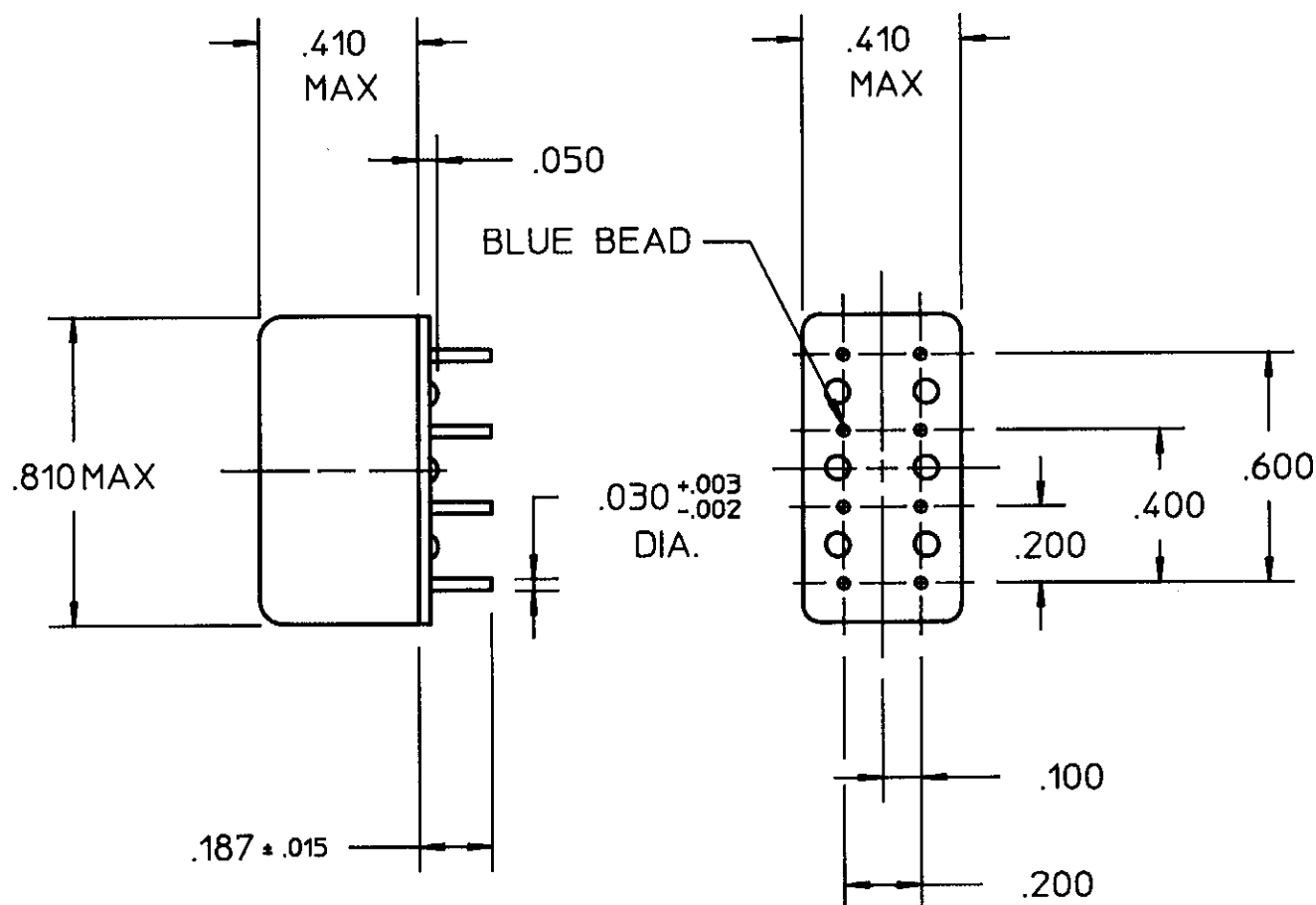

COIL: @ +25 °C

RESISTANCE 870 OHMS $\pm$ 10%

NOMINAL VOLTAGE 24.0 VDC

MUST OPERATE 17.5 VDC

MUST RELEASE 1.4 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's


SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 °C TO +85 °C

NOTES: 352 MILLIWATTS OPERATE SENSITIVITY

CUSTOMER DATA SHEET

BLUE BEAD

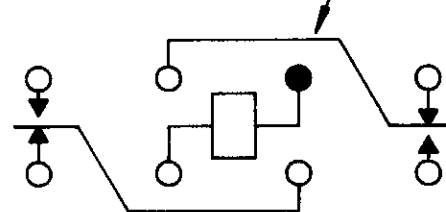

CONTACT RATING: 2A 30 VDC
RESISTIVE 100,000 OPERATIONS

DR. R.B. 10/16/91 CK. 10/16/91 JMB

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. EQUIVALENT TO HI-G
CUST. NO. FS2-2A-124P

TYPE "HFW" RELAY

HFW1201X201