




Color: ■ black

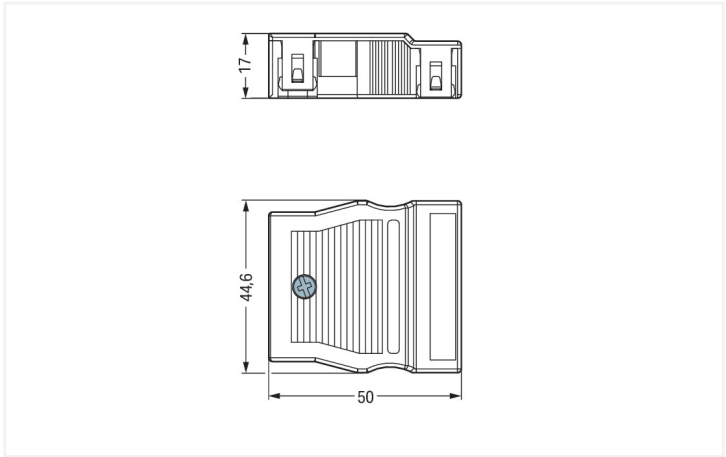

Dimensions in mm

Strain relief housing WINSTA® MIDI 4-pole

The strain relief housing from the WINSTA® MIDI product line guarantees you the greatest possible flexibility in electrical installation. An extensive range of accessories rounds out the WINSTA® product line from WAGO. The WINSTA® MIDI product line achieves maximum flexibility for the installation. With its Push-in CAGE CLAMP® spring pressure connection technology, it ensures error-free, time-saving installation and offers customization for meeting all installation requirements. A range up to 55 mm can be used for the strip length.

Push-in CAGE CLAMP® spring pressure connection technology – pluggable installation instead of laborious screw connections!

The WINSTA® Pluggable Connection System allows pluggable electrical installation. This significantly reduces the need for servicing and lowers costs. Take advantage of the pluggable version of our maintenance-free spring pressure connection technology too! Plan your installation with with protection against mismatching from WAGO.

- for automation controllers
- convenient installation and commissioning

Connection data	
Connection 1	
Pole number	4
Connectable sheathed cable diameter	9 ... 13 mm
Strip length (outer insulation)	55 mm

Physical data	
Pin spacing	10 mm / 0.394 inches
Width	44.6 mm / 1.756 inches
Height	17 mm / 0.669 inches
Depth	50 mm / 1.969 inches



Mechanical data		
Tightening torque of the screw		0.5 Nm

Material data		
Note (material data)		Information on material specifications can be found here
Color		black
Material group		I
Insulation material (main housing)		Polyamide (PA66)
Flammability class per UL94		V0
Fire load		0.361 MJ
Weight		11.8 g

 


Environmental requirements		
Processing temperature		-5 ... +40 °C
Continuous operating temperature		-35 ... +85 °C
Note on continuous operating temperature		Insulating parts for temperatures ≤ 105 °C

Commercial data		
Product Group		20 (Winsta)
PU (SPU)		25 pcs
Packaging type		Box
Country of origin		DE
GTIN		4017332755313
Customs tariff number		39269097900

Product classification		
UNSPSC		39121722
eCl@ss 10.0		27-44-06-92
eCl@ss 9.0		27-44-06-92
ETIM 9.0		EC002863
ETIM 8.0		EC002863
ECCN		NO US CLASSIFICATION

Environmental Product Compliance		
RoHS Compliance Status		Compliant, No Exemption

Approvals / Certificates

General approvals			Approvals for marine applications		
			 		
Approval	Standard	Certificate Name	Approval	Standard	Certificate Name
cURus Underwriters Laboratories Inc.	UL 1977	E45171	DNV GL Det Norske Veritas, Ger- manischer Lloyd	-	TAE00001Z6
cURus Underwriters Laboratories Inc.	UL 1059	E 45172	LR Lloyds Register	IEC 61984	LR22429487TA



Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 770-504

↓

Documentation

Bid Text				
770-504	19.02.2019	xml	2.73 KB	↓
770-504	12.03.2015	doc	23.50 KB	↓

CAD/CAE-Data

CAD data

2D/3D Models 770-504

↓

CAE data

EPLAN Data Portal 770-504

↓

WSCAD Universe 770-504

↓

ZUKEN Portal 770-504

↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking strip



Item No.: 210-333

Marking strips; as a DIN A4 sheet; Strip width 6 mm; Strip length 182 mm; plain; Self-adhesive; white