
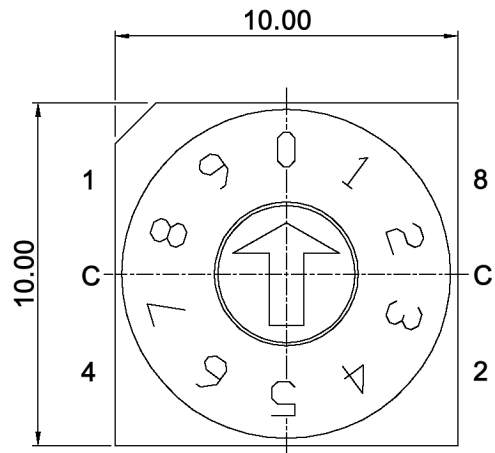
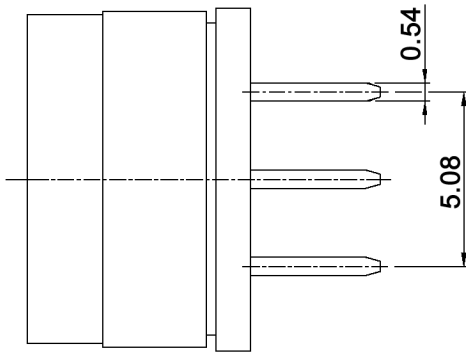
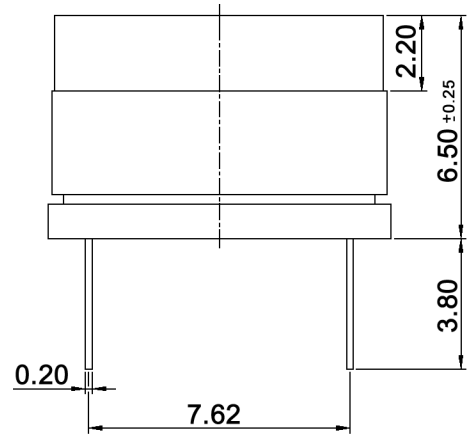


P.C.B. DIMENSION

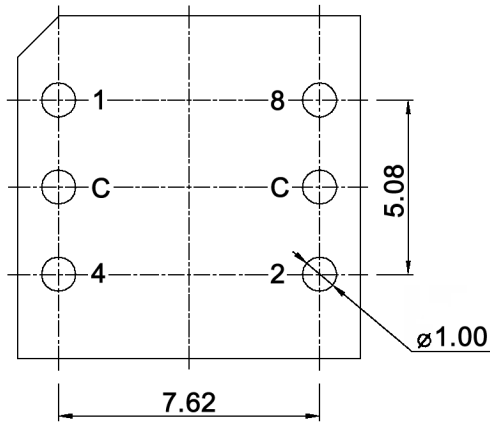

Specifications:

Contact rating:

switching: 25mA, 24V DC
non-switching: 100mA, 50V DC

Contact resistance:

80mOhm max.

Insulation resistance:

100MOhm min.

Mechanical life:

10 000 cycles

Operating force:

700gf max.

Operating temperature:

-40°C to +85°C

Storage temperature:

-40°C to +85°C

Soldering conditions:

pre-heat: max. 120°C, max. 70sec.
wave soldering: max. 260°C, max. 10sec.

Color of actuator:

grey

IP rating:

IP67

BCD

	Real coded				
	C	1	2	4	8
0	•				
1	•	•			
2	•		•		
3	•	•	•		
4	•			•	
5	•	•		•	
6	•		•	•	
7	•	•	•	•	
8	•				•
9	•	•			•



Tolerances:			Date	Name
			04/07	dr
Soldering conditions	01/11	dr		
IP rating	07/09	dr		
Operating temperature	11/08	dr		
Coding scheme	02/08	dr		
Temperatures	01/08	dr		
Modifications	Date	Name		

DRS 60010

knitter-switch

30 11 07

Page

1/1