
 


PAGE 1/1	ISSUE 10-04-15A	SERIES MML	PART NUMBER R302000000 XXX
----------	-----------------	------------	----------------------------

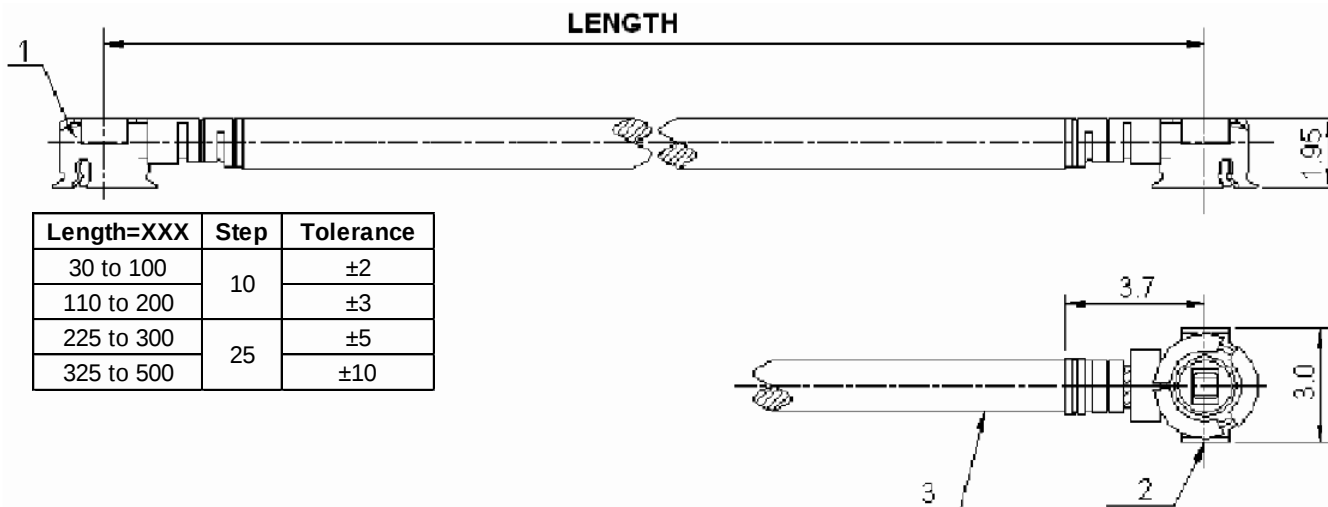

E.g. XXX=070 means length is 70±2, the part number is R302.000.000 070

All dimensions are in mm.



- * 1 * Connector A : MML H2.5 PLUG (gold plated)
- * 2 * Connector B : MML H2.5 PLUG (gold plated)
- * 3 * Cable 1.37/50S BLACK Type

ELECTRICAL CHARACTERISTICS

Impedance	50	Ω
Frequency	0-6	GHz
Operating temperature	-40/+90	° C
VSWR	1.3** + 0.000	x F(GHz) Maxi
Insertion loss	0.63*	√F(GHz) dB Maxi
Voltage rating	250	Veff Maxi
Dielectric withstanding voltage	300	Veff mini
Insulation resistance	500	MΩ mini

SPECIFICATION

Weight	0.800*	g
Cable retention	4	N mini
Mating life	30	Cycles

Others
****VSWR up to 3GHz 1.3 max**
Up to 6GHz 1.5 max

Length	*Insertion loss(Maxi)	*Weight(Maxi)
30 to 100	0.73 dB	3.00 g
110 to 200	1.16 dB	3.5 g
225 to 400	2.02 dB	4.10 g

Mating status

