


0805 X 4 BREAKOUT BOARD

SKU: ICB00380

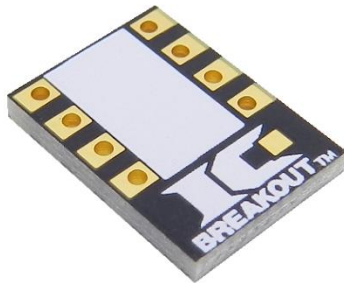


Description

The 0805 x 4 breakout board was designed to be a DIP adapter for 0805 type SMD components. The board will accommodate up to four 0805 parts.

Technical Details

Footprint Dimensions	
Body (mm):	n/a
Pitch (mm):	n/a
Thermal Pad (mm):	n/a
Breakout Board Dimensions	
Board Dimensions (mil):	410 x 575
Board Thickness (mil):	62
Through-Hole Spacing (mil):	300 mil (X-axis)
	100 mil (Y-axis)
Breakout Board Specifications	
Board Layers:	2
Finish:	Immersion Gold
Copper:	1 oz
Traces (mil)	10
Trace Lengths (mil):	<100
Pin/Through-Hole Count:	8

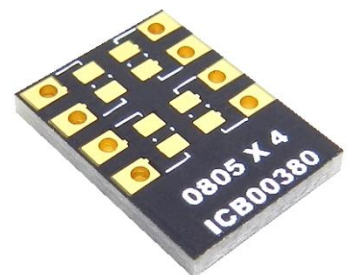


What's Included?

Parts Installed on Board:	None
Parts Included (but not installed):	24 PIN Break Away Header (Straight)

Additional Features

- Easily identifiable PIN 1 indicator and PIN numbers
- White silk “Label Pads” allow you to label the pins for quick reference
- Extended through-hole pads make for an easy connection point for surface mount parts
- Breadboard friendly pin spacing
- All boards have been E-tested for failures and are RoHS compliant

 
Scale Image




1:1 SCALE

(Print this page to use the scale image to test the fit of the electronic part.)

Dimensions

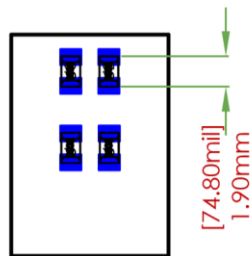

**FOOTPRINT
DIMENSIONS**

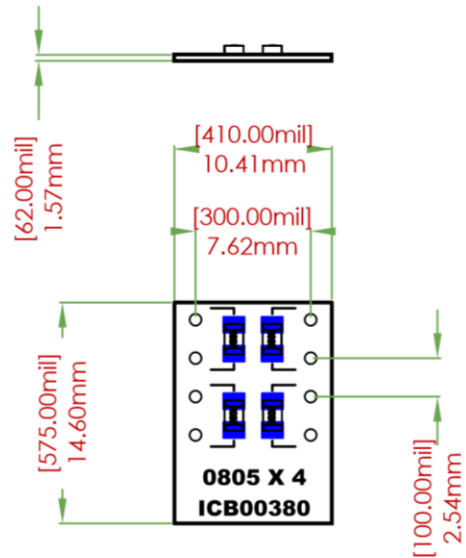

**BREAKOUT BOARD
DIMENSIONS**