


 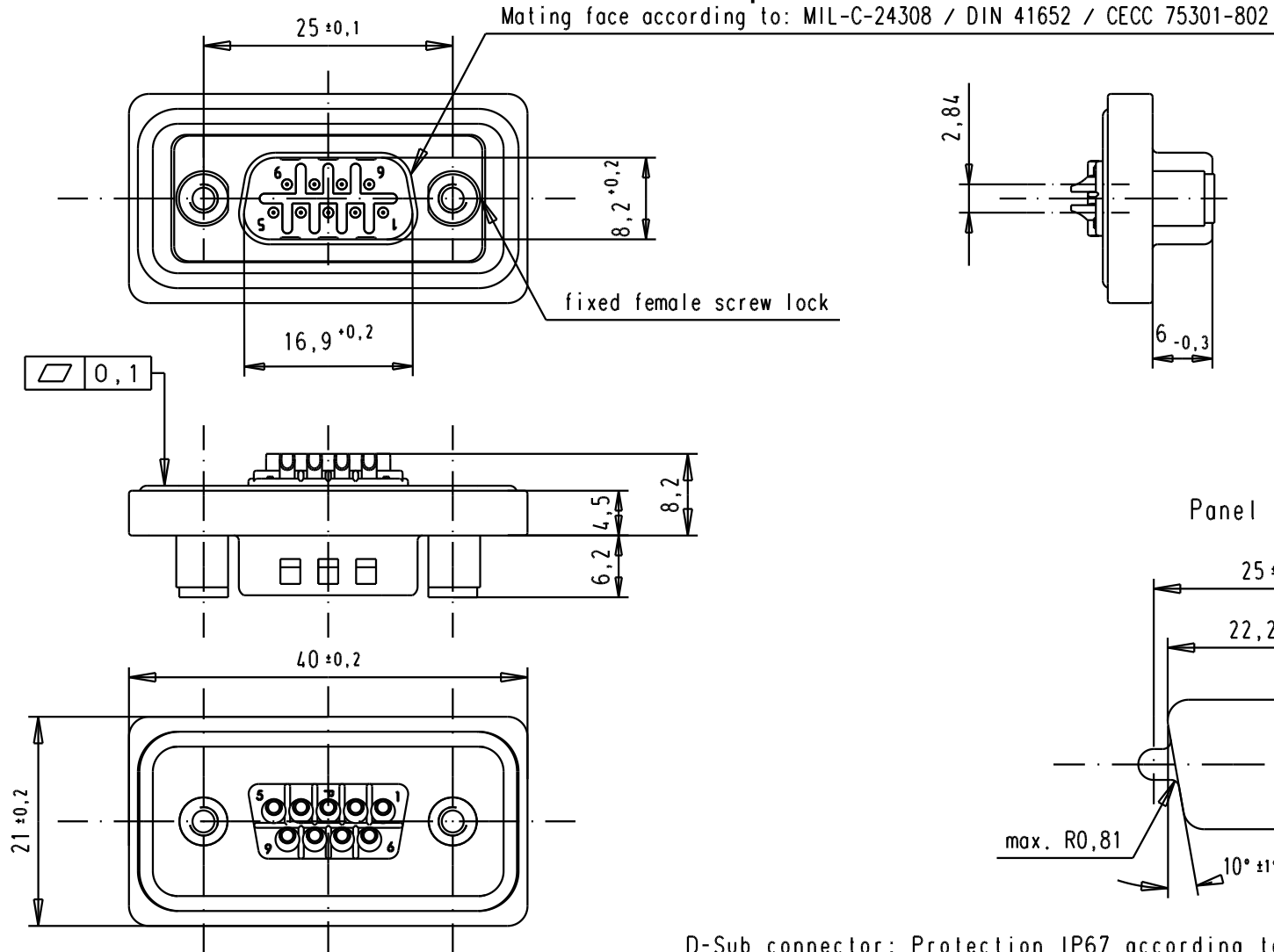


D-Sub connector: Protection IP67 according to DIN 40050

|                |            |
|----------------|------------|
|                |            |
|                |            |
|                |            |
|                |            |
| 09 67 709 9615 | M3         |
| 09 67 709 7615 | UNC 4-40   |
| Part number    | screw lock |

|       |          |      |
|-------|----------|------|
|       |          |      |
|       |          |      |
|       |          |      |
|       |          |      |
|       |          |      |
| 32156 | 02/09/04 | TR   |
| Mod.  | Dat.     | Name |

|                               |          |      |
|-------------------------------|----------|------|
|                               | Dat.     | Name |
| Detail.                       | 02/09/04 | TR   |
| Insp.                         |          |      |
| Stand.                        |          |      |
| HARTING EURL<br>F-95972 Paris |          |      |



All Dim. in mm  
Orig. Size DIN A 4



D-sub male 9 poles straight  
with solder buckets, front  
plastic plate and screw locks

TB09 67 709 X615

Sub.

Maßstab/  
Scale

1,5:1

Blatt/ Page

1/1