

BDHE002520121R5MQ1

Search by :

Part Number ➔

Characteristics ➡

Cross reference ➔



MP

Closed Magnetic Circuit Type

Molding Processing & for Ultra High Current

[Send Enquiry](#) 

Product detail

L(mm) ±	2.5±0.3
W(mm) ±	2.0±0.3
T(mm) ±	1.2Max.
Inductance(uH)	1.5
Tolerance(±%)	20
Test Frequency	2MHz,0.2V
RDC(Ω)Max	0.066
Isat(A)Typ	4.2
Isat(A)Max	3.4
Irms(A)Typ	3.1
Irms(A)Max	2.7

Operating Temperature

−40°C~125°C(Including self - temperature rise)


Part Numbering

Dimensions

Packing

Recommended Pattern

Electrical Characteristics

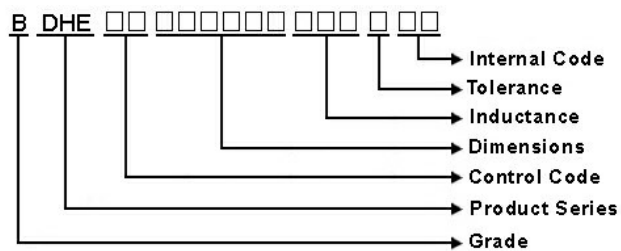

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.