

MultiMobile™ USB



V.92 Portable USB Modem

The MultiMobile™ USB portable USB modem, provides V.92/56K data rates, V.34/33.6K fax capabilities and a hot-swappable USB interface. This globally approved analog modem, weighing in at 2 ounces, is ideal for mission-critical out-of-band remote servicing, fax and data applications. The MultiMobile USB portable modem can also serve as the mobile user's desktop modem back in the office.




Features

- CDC-ACM compliant
- One-step installation into Windows, Linux and Macintosh operating systems
- V.92/56K downloads (from V.92 servers) and 33.6K data rates for uploads or peer-to-peer transfers
- V.44 compression improves data throughput rates
- Class 1.0 and 2.1 faxing at speeds to V.34/33.6K bps (Super G3)
- Error Correction Mode (ECM) provides fast and reliable fax transmissions
- Small footprint (measures only 1 × 3 inches)
- U.S. Caller ID reporting (Bellcore Type 1)
- LEDs show complete modem status
- Remote configuration for centralized setup and management
- Storage for two phone numbers for automatic dialing
- Global approvals in many countries for worldwide use
- Hot-swappable with other USB devices - no restarting or reconfiguring your PC
- Integrated USB cable simplifies setup and operation
- Flash memory for easy updates
- Two-year warranty

Benefits

- Easy to install
- Portable
- Hot-swappable
- Approved for worldwide use

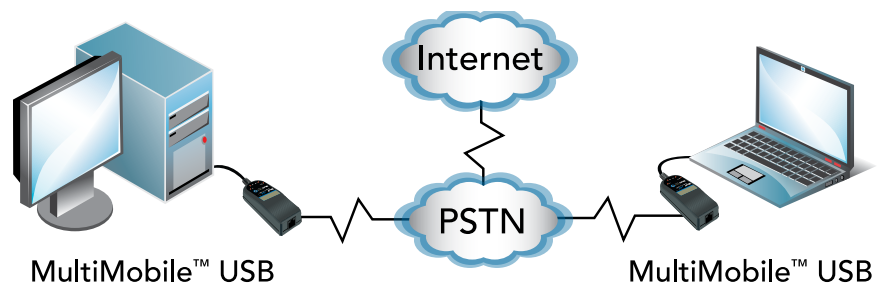

Specifications

Rates

Data: 56K download speeds from digital V.92/V.90 servers; 33.6K upload & download speeds from non-V.92/V.90 servers & other client modems

Fax: 33.6K & below

Standards

Data: V.92, V.90 enhanced V.34 & below

Error Correction: V.42

Data Compression: V.44, V.42bis, MNP Class 5

Fax: V.34, Class 2.1 & 1.0, V.17, Group 3; Class 1 & 2, Error Correction Mode (ECM)

Video: V.80

Power Requirements

Maximum

Watts: 890mW

Voltage: 5.01V

Current: 178mA

Cables

1 USB series A & 1 RJ-11

Operation

USB Port: USB 2.0 Full Speed 12M bps

Line Type: Dial-up

Operating System Support

Windows server 2012/2008/XP/2003/Vista/7/8, Linux, & Mac OS X

CDC-ACM compliant

Physical Description

1.3" w x 1.0" h x 3.1" d; 2 oz

(3.0 cm w x 2.5 cm h x 8.0 cm d; 62 g)

Operating Environment

Operating Temp: -31° to +167° F (-35 to +75° C)

Humidity Range: 25-85% noncondensing

Approvals

CE Mark

EMC: FCC Part 15 Class B, EN 55022 Class B, EN 55024

Safety: c/UL 60950-1, IEC 60950-1

Telecom: 47CFR Part 68, CS03, TBR21, other countries also included

Services & Warranty

Multi-Tech's comprehensive Support Services programs offer a full array of options to suit your specific needs. These services are aimed at protecting your investment, extending the life of your solution or product, and reducing total cost of ownership. Our seasoned technical experts, with an average tenure of more than 10 years, can walk you through smooth installations, troubleshoot issues and help you with configurations. Products include a 2-year warranty that can be extended up to 5 years via Multi-Tech's Extended Warranty program, which offers the convenience of Overnight Service* for optimal uptime.

Extended Warranty & Overnight Services

To give you peace-of-mind and protect your investment, our Extended Warranty Service Plans ensure your Multi-Tech products are covered for 1, 2, or 3 years beyond the manufacturer's warranty with an optional Overnight Service plan*.

Installation Support

Multi-Tech's Installation Support Service delivers priority service with the ability to work one-on-one with an experienced Multi-Tech technical support engineer, to guide you through the installation process for our products.

Technical Support Services

At Multi-Tech, we're committed to providing you personalized attention and quality service while providing you a quick response to your product support needs. We have several options of support for you to choose from.

For additional information on Support Services as well as other service offerings, please contact your Multi-Tech representative or visit www.multitech.com/support.go.

* Overnight replacement service is currently available for U.S. customers.

World Headquarters

Multi-Tech Systems, Inc.
2205 Woodale Drive
Mounds View, MN 55112 U.S.A.
Tel: 763-785-3500
Toll-Free: 800-328-9717
Email: sales@multitech.com
www.multitech.com

EMEA Headquarters

Multi-Tech Systems (EMEA)
United Kingdom
Tel: +(44) 118 959 7774
Email: sales@multitech.co.uk

Ordering Information

Product	Description	Region
MT9234MU-CDC-XR	V.92 Portable Data/Fax World Modem (USB)	Global

Produced in the U.S. of U.S. and non-U.S. components. Features and specifications are subject to change without notice.

Trademarks and Registered Trademarks: Multi-Tech and the Multi-Tech logo, MultiMobile: Multi-Tech Systems, Inc. All other products and technologies are the trademarks or registered trademarks of their respective holders.

7/14 • 86002072 • © 2014 by Multi-Tech Systems, Inc. All rights reserved.

