




Part Number : [982670477](#)

Product Description : 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 178.00mm Cable Length, Tin (Sn) Plating, 30 Circuits

Series Number : 98267

Status : Active

Product Category : Flat-Flexible Cable (FFC)

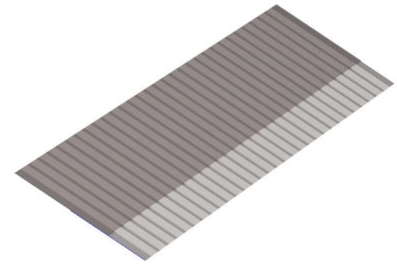

Documents and Resources

Drawings

[982670477 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[PS-98267-001-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Not Relevant |
| China RoHS |  per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2023)8585-DC (23 Jan 2024) |
| EU RoHS | Compliant per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|---|
| Status | Active |
| Category | Flat-Flexible Cable (FFC) |
| Series | 98267 |
| Description | 1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 178.00mm Cable Length, Tin (Sn) Plating, 30 Circuits |
| Comments | Contacts on the same side, Type A |
| Product Name | Premo-Flex FFC Jumper |
| UPC | 756054775325 |

Electrical

| | |
|-------------------------------|--------|
| Current - Maximum per Contact | 1.2A |
| Voltage - Maximum | 60V AC |

Physical

| | |
|---------------------------|----------------|
| Cable Length | 178.00mm |
| Circuits (Loaded) | 30 |
| Contact Layout Type | A (same side) |
| Design Feature | Extra-Flexible |
| Material - Plating Mating | Tin |
| Net Weight | 3.928/g |
| Packaging Type | Bag |
| Pitch - Mating Interface | 1.00mm |

| | |
|-------------------------------|-----------------|
| Temperature Range - Operating | -40° to +105°C |
| Termination Style | FFC Connector |
| Wire/Cable Type | Flat Flex Cable |
| Wire Size (AWG) | N/A |

Mates With / Use With

Mates with Part(s)

| Description | Part Number |
|--|----------------------------------|
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 30 Circuits, Tin-Bismuth Plating | <u>522713079</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 30 Circuits, Tin-Bismuth Plating | <u>526103071</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 30 Circuits, Tin-Bismuth Plating, with Pick-and-Place Tape | <u>526103075</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, 30 Circuits | <u>528083070</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 30 Circuits | <u>528083071</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Top Contact, 2.70mm Height, 30 Circuits, Tin-Bismuth Plating | <u>522073085</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 30 Circuits | <u>527933070</u> |

| | |
|---|------------------|
| 1.00mm Pitch Easy-On FFC/FPC Connector, Vertical, Surface Mount Compatible, Non-ZIF, Kinked PC Tails, 30 Circuits | <u>528063010</u> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Non-ZIF, Top Contact Style Receptacle, 30 Circuits | <u>528073010</u> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Right-Angle, Non-ZIF, Bottom Contact Style, 30 Circuits | <u>528523070</u> |

This document was generated on Dec 26, 2025