


**Product Line**

- DeepTronica >
- Single Pair Ethernet >
- ZConnect >
- Ceres >
- X-Lok >
- Accessory
- Middle Size
- Mini Size
- Large Size
- Standard Size**
- M Series >
- FLOS & FLOS+ >
- Power >
- RBL >
- HS-Lok >
- NMEA 2000 >
- Heavy Duty Shielded >
- RJ >
- USB >
- SSL >
- HDMI >
- DVI >
- Fiber Optic >
- RF >
- Cable Joiner >
- Cable Gland >
- Pressure Relief Vent >
- LED Light Guide >
- D-Sub >

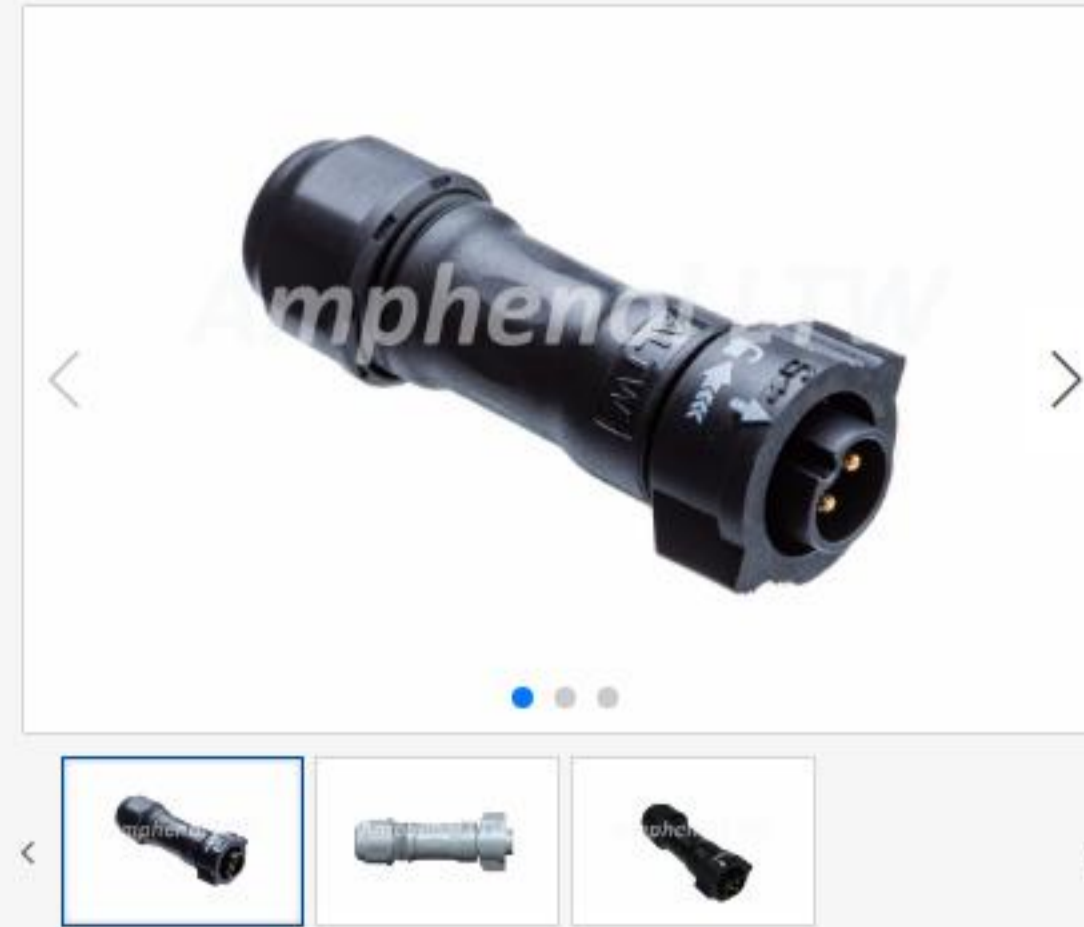

**BD-02BFMA-QL8MPO**

Operating Temperature: -40°C ~ +105°C  
 Transmission Speed: N/A  
 Shielded: Plastic, Non-shielded  
 Jacket Material: N/A  
 Certificate: UL1977

You must login first for view the price

Quantity

Can't find? [Customize your part](#)

**Mating Pair & Accessories**

Connector Type

X-Lok, Standard... AB-BD02FL-BDHL -20°C ~ +80°C	X-Lok, Standard... AB-BD02FL-BDHL -20°C ~ +80°C	X-Lok, Standard... AB-BD02FL-BDHL -20°C ~ +80°C	X-Lok, Standard... AB-BD02FL-BDHL -20°C ~ +80°C	X-Lok, Standard... AB-BD02FL-BDHL -20°C ~ +80°C	X-Lok, Standard... AB-BD02FL-BDHL -20°C ~ +80°C
<input type="text" value="0"/>	<input type="text" value="0"/>	<input type="text" value="0"/>	<input type="text" value="0"/>	<input type="text" value="0"/>	<input type="text" value="0"/>
<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>	<input type="checkbox"/>

Specifications	Download / CAD
Nominal Current <b>5A</b>	Connector Type <b>Field Installable</b>
Shielded <b>Plastic, Non-shielded</b>	No. of Contacts <b>02</b>
Connector Gender <b>Female</b>	Backshell <b>Straight</b>
Mating Style <b>Push Lock</b>	IP Rating <b>IP68</b>
Assembly Style <b>Crimp</b>	

[More Options](#)

**People Also Bought**

