

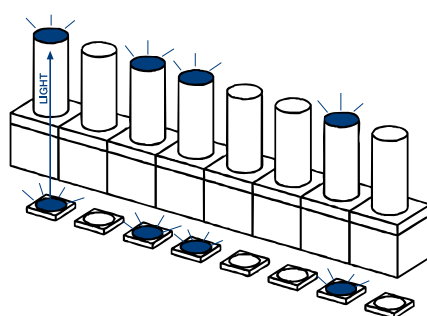


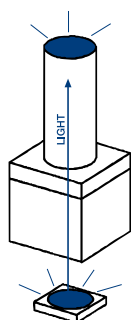


Series KSMZ01-XX

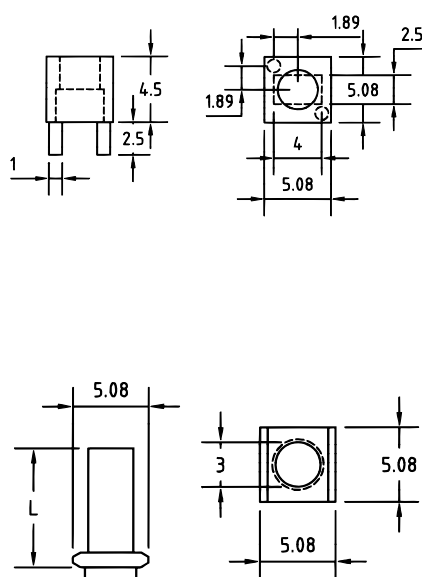

Dimensions in mm (typical)

Series KSMD08-XX

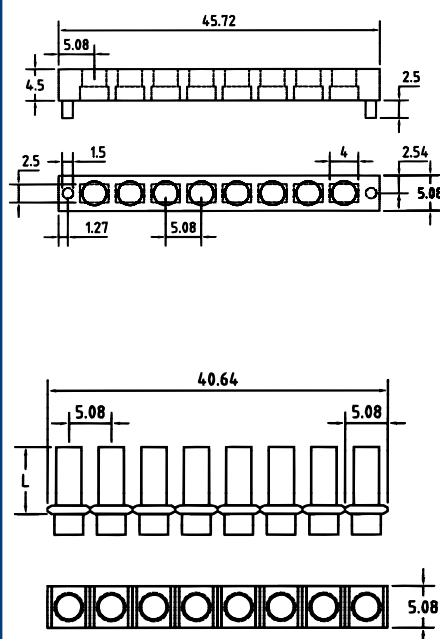

Dimensions in mm (typical)

Type	Length
KT-02	L = 2 mm
KT-04	L = 4 mm
KT-054	L = 5,4 mm
KT-06	L = 6 mm
KT-075	L = 7,5 mm
KT-085	L = 8,5 mm
KT-10	L = 10 mm
KT-13	L = 13 mm
KT-15	L = 15 mm
KT-17	L = 17 mm
KT-20	L = 20 mm
KT-25	L = 25 mm
KT-30	L = 30 mm
KT-37	L = 37,9 mm
KT-40	L = 40 mm
KT-45	L = 45 mm
KT-47	L = 47,5 mm
KT-50	L = 50 mm
Your length	L =

- The code: KT-XX refers only to the transparent part.
On the grounds of the desired length KT-XX can be supplied in rows of 3 or 8 places. We supply the complete device, that is black together with transparent part and the full code will be as follows:
For example:
KSMD08 + KT30 = KSMD 08-30

RECOMMENDED LEDs:

Size	Color	Range intensity (mcd)
0805	All	2÷60
0603	All	10÷60

BENEFITS

- ◆ ESD protection electrostatic discharge;
- ◆ High transmissivity, delivery maximum light transmission;
- ◆ Helps to eliminate mixed technology PCB processing;
- ◆ Secures to PCB or front panel by snap-in or press-fit;
- ◆ Wide viewing angle;
- ◆ Special shapes and symbols;
- ◆ Reduce insertion cost.

One of many applications

