




150 mm sq. type

Model no.	Surface treatment	Mass (g)
109-1051	Nickel-chrome plating (silver)	63

Model no.	Surface treatment	Mass (g)
109-1052	Nickel-chrome plating (silver)	53


ø150 mm type

Model no.	Surface treatment	Mass (g)
109-1104	Nickel-chrome plating (silver)	31
109-1104H	Cation electropainting (black)	

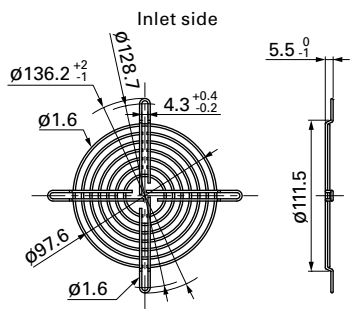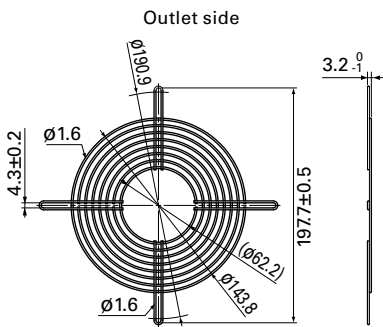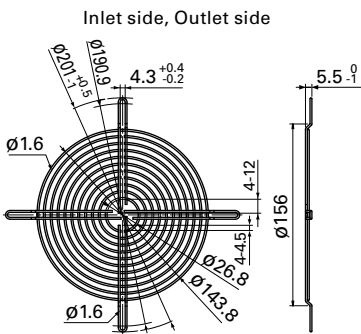

Mounting example

Axial fan

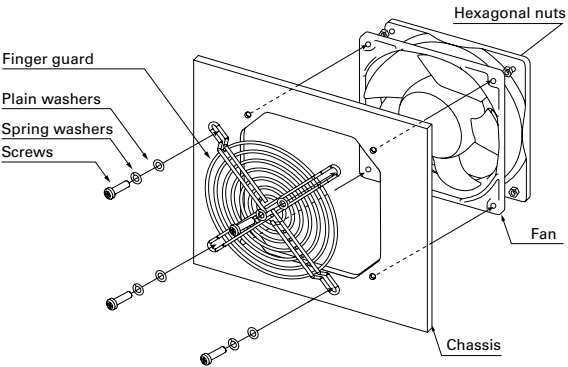

Centrifugal fan

