

Part Number : [190700051](#)


Product Description : InsulKrimp Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 10 (M5), Length 20.73mm, Red, Carton

Series Number : 19070

Status : Active

Product Category : Ring and Spade Terminals

Engineering Part Number : AA-233-10X

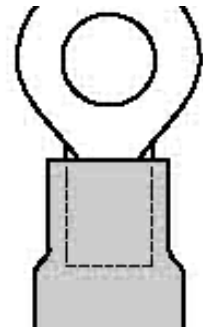

Documents and Resources

Drawings

[190700051_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


Specifications

[PS-19902-009-001.pdf](#)

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19070
Description	InsulKrimp Ring Tongue Terminal for 22-18 AWG Wire, Stud Size 10 (M5), Length 20.73mm, Red, Carton
Keyword	Ring Terminal, Ring Terminals
Product Name	InsulKrimp
Style	Ring
Type	Ring Terminal, Metric Ring Terminal
UPC	800753069084

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Color - Resin	Red

Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	0.498/g
Packaging Type	Carton
Stud Size	10 (M5)
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	3.70mm max.
Wire Size (AWG)	18, 20, 22
Wire Size mm ²	0.35-0.80

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>192830001</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>192830003</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>192830006</u>
Hand Crimp Tool	<u>192850004</u>
Hand Crimp Tool	<u>192850006</u>
Hand Crimp Tool	<u>192850010</u>
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 22-10 AWG and 6.0-0.5mm ² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010100</u>
PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 22-10 AWG (Rings, Spades, Hooks, Block Spades and	<u>640010300</u>

Flanged Spades)	
Hand Crimp Tool	<u>640011200</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050300</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640051200</u>
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	<u>640160036</u>

This document was generated on May 20, 2026