


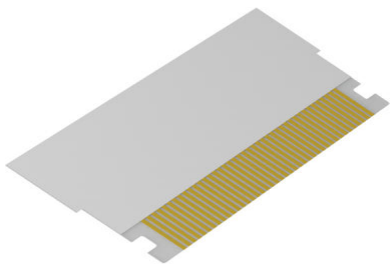

**Part Number :** [150230841](#)  
**Product Description :** 0.50mm Pitch Premo-Flex  
LVDS Jumper, 203.00mm Cable Length, Gold (Au)  
Plating, 41 Circuits  
**Series Number :** 15023  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings

- [150230841 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [150230001-000.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15023
Description	0.50mm Pitch Premo-Flex LVDS Jumper, 203.00mm Cable Length, Gold (Au) Plating, 41 Circuits
Product Name	Premo-Flex LVDS Jumper
UPC	889056697590

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	30V AC

**Physical**

Cable Length	203.00mm
Circuits (Loaded)	41
Contact Layout Type	A (same side)
Design Feature	High-Speed
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +80°C
Termination Style	FFC Connector

Wire/Cable Type	Flat Cable
Wire Size (AWG)	N/A

---

### Mates With / Use With

#### Mates with Part(s)

Description	Part Number
0.50mm Pitch Easy-On One-Touch Family FFC/FPC Connector for LVDS, Non-ZIF, with Side Locks, Bottom Contact Style, 3.75mm Height, Right-Angle, Surface Mount, 41 Circuits	<u>5039084120</u>

---

This document was generated on Sep 17, 2025