




Part Number : [2209570122](#)

Product Description : T1 Industrial Single-Pair Ethernet (SPE) M12 Plug Cable Assembly, IP65/67, 10.0m Cable Length

Series Number : 220957

Status : Active

Product Category : I/O Cable Assemblies

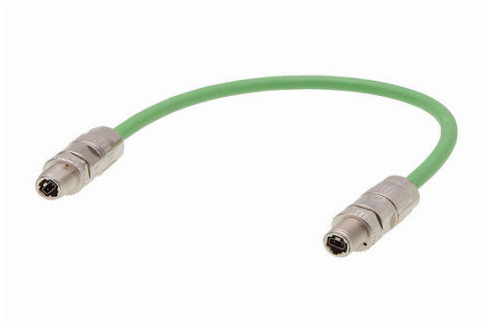

Documents & Resources

Drawings

[2209570122_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	I/O Cable Assemblies
Series	220957
Description	T1 Industrial Single-Pair Ethernet (SPE) M12 Plug Cable Assembly, IP65/67, 10.0m Cable Length
Assembly Configuration	Dual Ended Connectors
Connector to Connector	SPE-to-SPE
Product Name	Single-Pair Ethernet (SPE)
UPC	196823192579

Electrical

Current - Maximum per Contact	4.0A
Data Rate	Up to 1.0 Gbps
Shielded	Yes
Voltage - Maximum	60V AC

Physical

Cable Length	10.0m
Circuits (Loaded)	2
Circuits (maximum)	2
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Metal	Copper
Material - Plating Mating	Gold
Packaging Type	Bag
Single Ended	No
Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65, IP67
Wire/Cable Type	PUR, Twisted Pair
Wire Size (AWG)	1 x 2 x AWG 22/19

This document was generated on Oct 01, 2025