
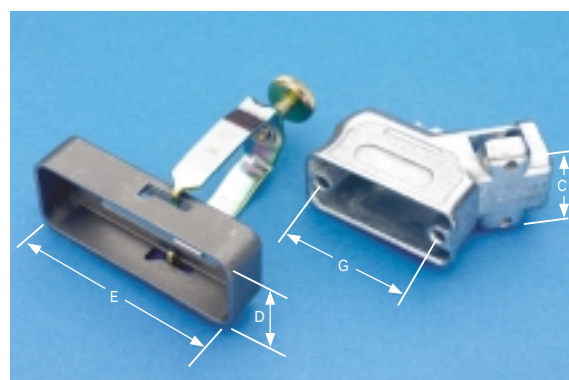


Features

- BT 217 approved
- Solid die cast construction
- Positive termination of screen using pre-tapped hole
- Cover may be used with slide locks or base retainer

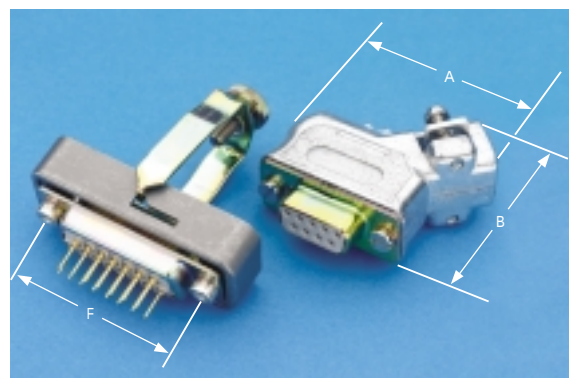

Shell Size	Dimensions (mm)						
	A	B	C	D	E	F	Cable Outlet
E	40.4	33.5	20.6	18.0	35.7	24.99	9.52
A	48.4	33.5	20.6	18.0	44.4	33.32	9.52
B	60.0	39.5	20.6	18.0	58.0	47.04	9.52
C	76.4	39.5	20.6	18.0	74.6	63.50	9.52
D	74.9	39.9	23.4	20.8	72.0	61.11	12.70

Shell Size	Standard Hoods with 6BA Screws	Hoods with Mounting Holes Tapped 4-40 UNC for use with Slide locks	Base Retainer Part Number Screw Down Version	Base Retainer Part Number Spring Clip
E	217-9H	217-9HT	217-9RTB	217-9R
A	217-15H	217-15HT	217-15RTB	217-15R
B	217-25H	217-25HT	217-25RTB	217-25R
C	217-37H	217-37HT	217-37RTB	217-37R
D	217-50H	217-50HT	217-50RTB	217-50R