


Front plate - SI-FP-R1A-D1B-D3B - 1404502

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

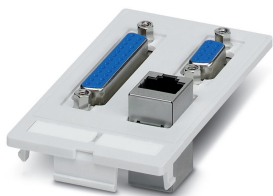

Data front plate with contact inserts, plastic with shroud, 1 x RJ45, 8-pos. metal, CAT5e (socket/socket); 1 x D-SUB 9 (socket/pin), 1 x D-SUB 25 (socket/pin)

RoHS

Key Commercial Data

Packing unit	1 pc
GTIN	 4 046356 698443
GTIN	4046356698443
Weight per Piece (excluding packing)	60.000 g
Custom tariff number	85366990
Country of origin	Czech Republic

Technical data

Mechanical characteristics

Shielded	yes
Degree of protection	IP20
Contact insert design	with 1x D-SUB 9 Socket/pin, slot locking UNC 4...40 bolts
	with 1x D-SUB 25 Female/t, slot locking, UNC 4...40 bolts
	with 1x RJ45 Socket/socket, snap-in slot locking

Ambient conditions

Ambient temperature (operation)	-10 °C ... 60 °C
---------------------------------	------------------

Material data

Material	PBT (Front plate)
Depth	21 mm

Front plate - SI-FP-R1A-D1B-D3B - 1404502

Technical data

Material data

Height	87.5 mm
--------	---------

Electrical characteristics


Rated voltage (III/3)	48 V AC/DC (D-SUB 9 / D-SUB 25)
Rated current	3 A (D-SUB 9, D-SUB 25)

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

Drawings

Dimensional drawing

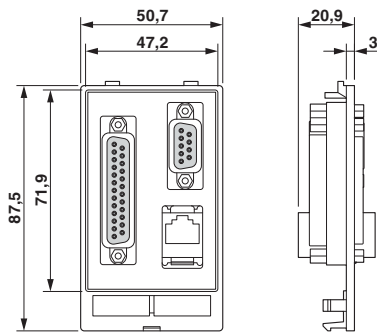

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	27182806
eCl@ss 4.0	27140800
eCl@ss 4.1	27140800
eCl@ss 5.0	27189200
eCl@ss 5.1	27189200
eCl@ss 6.0	27189200
eCl@ss 7.0	27189217
eCl@ss 9.0	27189217

Front plate - SI-FP-R1A-D1B-D3B - 1404502

Classifications

ETIM

ETIM 3.0	EC000007
ETIM 4.0	EC001855
ETIM 6.0	EC000456
ETIM 7.0	EC000456

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	39121302
UNSPSC 18.0	39121302
UNSPSC 19.0	39121302
UNSPSC 20.0	39121302
UNSPSC 21.0	39121302

Accessories

Accessories

Device marking

Snap-in markers - UCT-EM (20X7) - 0801494



Snap-in markers, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: snapped into marker carrier, lettering field size: 20 x 7 mm, Number of individual labels: 24