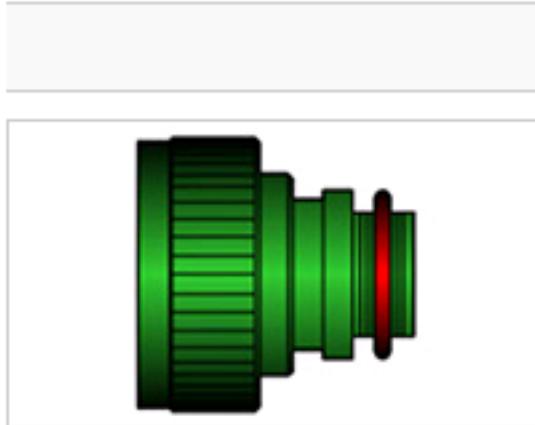


## TXR40AZ00-1004AI Product Details


**Active**

### Braid, Fixed, Spin and Tinel Lock Adapters

TXR40AZ00-1004AI

**TXR40AZ00-1004AI**
*TE Internal Number: CB4935-000*
 Share

 Print

 Email

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

[Feedback](#)
[Documents](#)
[Features](#)
[Compliance](#)
**Please Note:**
*Use the Product Drawing for all design activity*
**Product Type Features**
**Style**  Tinel Lock

**Angle**  Straight

**Connector Shell Size** 10

**Finish** Zinc Nickel

**Color** Black (Non Reflective)

**Dimensions**
**Boot Diameter (mm [in])**  13.97 [0.550]

**Cable Diameter Range (mm [in])** 3.50 – 5.50 [0.140 – 0.220]

**Body Features**
**Connector Code**  40

**Entry Size** 4

**Material** Aluminum Alloy

**Configuration Features**
**Braid**  Single 36 AWG Braid

**Industry Standards**
**Government/Industry Qualification**  No

**Military Style Number** MIL-C-38999

**RoHS/ELV Compliance**  Not ELV/RoHS compliant

**Lead Free Solder Processes**  Not relevant for lead free process

**Conditions for Usage**
**Applies To** Cable

**Other**
**Brand** Raychem

**Comment** For specific shell size information, refer to "Harnware" or Catalog.

**Related Products**

Not quite the product you're looking for?

[Find Similar Products](#)
[View Part in Product Feature Selector](#)
[Check for Tooling](#)
**Corporate Information**
[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)
[Global Accessibility Statement](#)
**Quick Links**
[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)
**Customer Support**
[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)
**Keep Me Informed**
