

Honeywell Sensing and Control

Search

narrow your search

Products

- Controls Monitoring and Lighting (286)
- Machine Safety (1727)
- Sensors (6004)
- Switches (9781)
- Wireless (45)

Technology

- Control and Instrumentation (988)
- Electromechanical (9307)
- Magnetic (541)
- Platinum thin film (56)
- Thick Film (1409)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site
WGLA and WPMM
XYR6000™

find out more

white papers

 
- ▶ Wireless Switches Offer Unlimited Benefit
- ▶ Basic Switches Are Not Created Equal
- ▶ Applying Precision Switches
- ▶ Sensors for Medical Devices
- ▶ New Ways to Measure Torque
- ▶ Choosing Safety Switches
- ▶ Specifying Hour Meters

Need help?

Click here to contact us

1TL163-7

(Home : Products : Switches » MICRO SWITCH™ Toggle Switches » TL)



TL Series Toggle Switch, 1 pole, 3 position, Screw terminal, Special Design Lever

Actual product appearance may vary.


Sales & Service

Distributor Inventory

Overview Specs Documentation Application Notes

Product Specifications

Circuitry/Operating action

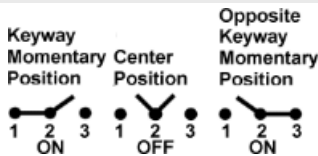

Product Type	MICRO SWITCH™ Toggle Switch
Ampere/Voltage Range (Resistive Load)	0.5 A at 250 Vdc, 0.75 A at 115 Vdc, 0.5 A to 15 A at 0.5 Vdc to 28 Vdc, 0.5 A to 10 A at 0.5 Vac to 277 Vac
Circuitry	SPDT
Action	3 position
Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Special Design
UL/CSA	L192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"
Comment	Silver cadmium oxide contacts
Availability	Global
UNSPSC Code	30211908
UNSPSC Commodity	30211908 Toggle switches
Series Name	TL

contacts

- ▶ Customer Service
- ▶ Technical Support
- ▶ Global Sales & Service
- ▶ View Site Demo
- ▶ Site Comments?

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.

▶ Meet Dr. Larry

my links

- ▶ Login to iCOM
- ▶ Login to Rep/AD Portal
- ▶ Login to Digital University

News Center

- ▶ HONEYWELL EXPANDS ITS LIMITLESS™ PLATFORM WITH THE LAUNCH OF ITS GLOBALLY AVAILABLE INDUSTRIAL WIRELESS RECEIVER
- ▶ HONEYWELL EXTENDS ITS TRUSTABILITY® PRESSURE SENSOR PRODUCT LINE WITH A SINGLE SIDE LIQUID MEDIA OPTION
- ▶ HONEYWELL ADDS NEW 100° AND 180° ARC CONFIGURATIONS TO ITS SMART POSITION SENSOR PORTFOLIO
- ▶ HONEYWELL INTRODUCES ITS HAWK™ RESOLVERS 1-INCH SERIES, FULLY HOUSED CONFIGURATION
- ▶ HONEYWELL INTRODUCES MICROPOWER OMNIPOLAR DIGITAL HALL-EFFECT SENSOR ICS WITH LOW SUPPLY VOLTAGE AND ULTRA LOW TYPICAL CURRENT



MICRO SWITCH Anniversary site