



Search Results

- Evaluate
- FAQ's
- How to Buy
- Bill of Material
- Favorite Products List
- Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click to remove) Search Tips Within Results

Text Search: 'GE255-L'

Your search criteria matched only one product, shown below

GE255-L

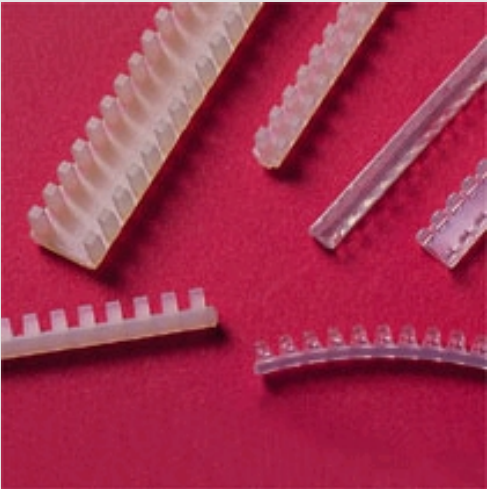

	Part Number	GE255-L
	RoHS Compliancy Status	Compliant
	Part Description	Military Specification Nylon Grommet Edging in 12.75" strips.
	Material	Nylon 6.6
	Color	Natural
	Military Specification	MS21266-5N
	Height (In.)	.24
	Height (mm)	6.1
	Length (In.)	12.75
	Length (mm)	323.9
	Width (In.)	.39
	Width (mm)	9.8
	Flammability Rating	UL94 V-2
	Outside Depth (In.)	.240
	Outside Depth (mm)	6.1
	Outside Width (In.)	.385
	Outside Width (mm)	9.8
	Panel Thickness Range (In.)	.192 – .255
	Panel Thickness Range (mm)	4.9 – - 6.5
	Pricing Description	Grommet Edging, Slot Strip, Nylon, Natural
	Temperature Range	-40°F to 149°F (-40°C to 65°C)
	Min. Order UOM	PC
	Min. Order Qty.	50
	BOM Qty. (# of Pkgs.)	0
	Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.