

Han Pneumatic module, for 6mm contacts

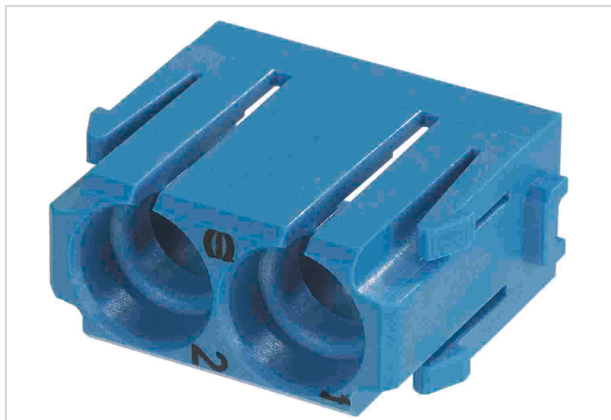


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 002 4501
Specification	Han Pneumatic module, for 6mm contacts
HARTING eCatalogue	https://b2b.harting.com/09140024501

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® Pneumatic module

Version

Gender	Male Female
Number of contacts	2
Details	Please order contacts separately. Using of guiding pins is imperative!

Technical characteristics

Limiting temperature	-40 ... +80 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	Blue
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No



Pushing Performance

Material properties

REACH SVHC substances	No
-----------------------	----

Specifications and approvals

Specifications	IEC 61984
	EN 60664-1
Approvals	DNV GL
UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076

Commercial data

Packaging size	2
Net weight	6.8 g
Country of origin	Germany
European customs tariff number	85389099
eCl@ss	27440220 Module for industrial connectors (pneumatic)