

Resonators > CERALOCK (kHz) > Series

How to check EU RoHS Comliant of Our Products is [here](#).

Product Lifecycle Stage	in Production
Recommended Rank	Preferred

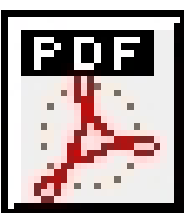
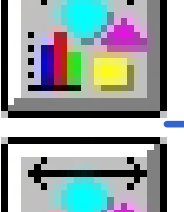
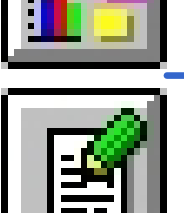
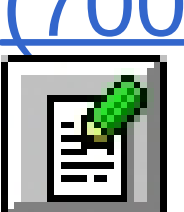
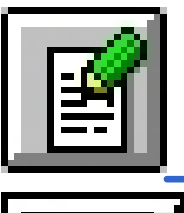
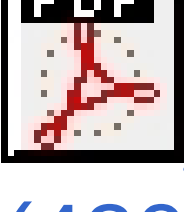
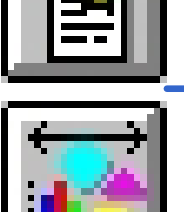
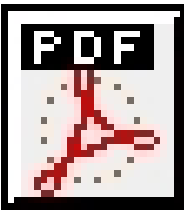
Specification

Global Part Number	CSBFB_J
Previous Part Number	CSBF_J
Oscillating Frequency	430 to 519kHz, 700 to 1250kHz
Initial Tolerance	±0.5%
Temp. Stability	±0.3%
Temperature Range	-20 to 80°C
Wash	Available
Ultrasonic Wash	Available
Capacitor	External
Frequency Tolerance	Available in ±0.3%,±0.2%,±1kHz,±2kHz
Use	
Airtightness	Washable

Minimum Quantity

180mm Paper Tape	
180mm Embossed Tape	
330mm Paper Tape	
330mm Embossed Tape	
Bulk Case	
Bulk(Bag)	
Ammo Pack	
320Reel	
Magazine	
Box	

Details

- ?  [Part Numbering](#)
- ?  [Appearance_\(430_to_519kHz\)](#)
- ?  [Dimensions_\(430_to_519kHz\)](#)
- ?  [Appearance/Dimensions_\(700_to_1250kHz\)](#)
- ?  [Features_and_Applications](#)
- ?  [Temperature_Characteristics](#)
- ?  [Basic_Oscillation_Circuit](#)
- ?  [Standard_Land_Pattern_Dimensions_\(430_to_519kHz\)](#)
- ?  [Standard_Land_Pattern_Dimensions_\(700_to_1250kHz\)](#)
- ?  [Notice_\(storage_and_operating_condition\)](#)
- ?  [Notice_\(rating\)](#)
- ?  [Notice_\(soldering_and_mounting\)_\(430_to_519kHz\)](#)
- ?  [Notice_\(soldering_and_mounting\)_\(700_to_1250kHz\)](#)
- ?  [Notice_\(handling\)](#)
- ?  [Packaging_\(430_to_519kHz\)](#)
- ?  [Packaging_\(700_to_1250kHz\)](#)
- ?  [Minimum_Quantity\[Supplementation\]](#)

Please approve our product specifications or to transact the approval sheet for product specifications before ordering. Please read rating and !Cautions first.
Product specifications in this catalog are as of January 2008.

All products and company names herein are trademarks or registered trademarks of their respective owners.