



Electrical Commercial and Industrial

- Products
- Documentation & Literature
- News & Tradeshow
- Support


United States > All 3M Products > Market Segments > Electronics, Electrical, and Communications > Electrical Products > Electrical Commercial and Industrial > Products > Electrical Commercial & Industrial Products Catalog > Terminals, Kits and Tools > Terminals > 3M™ Highland™ Male Disconnects > 3M™ Highland™ Nylon Fully Insulated Male Disconnect Terminal MTI18-250Q, AWG 22-18, 25/bag

- [Find An Account Rep](#)
- [Where To Buy \(Find A Distributor\)](#)
- [Contact Us](#)

3M™ Highland™ Nylon Fully Insulated Male Disconnect Terminal MTI18-250Q, AWG 22-18, 25/bag

3M ID 80611602873 UPC# 00051128600269 3M Product Number MTI18-250Q

Print Share

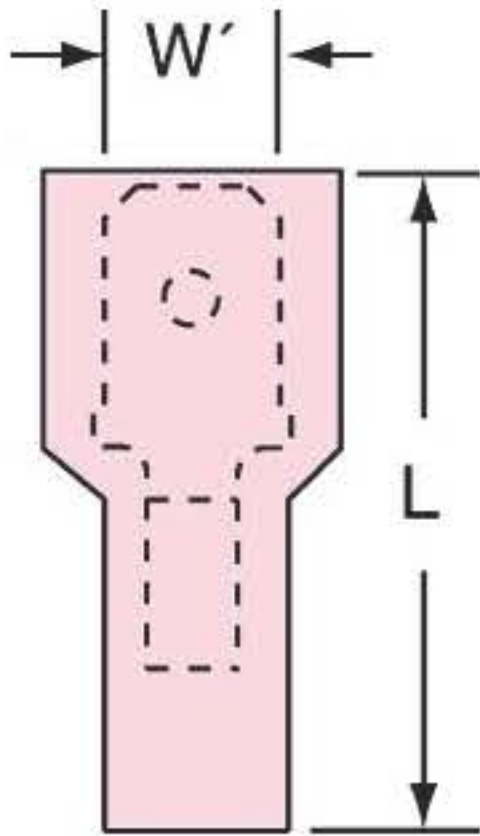

This tab accepts a wire range of 22-18, a stud/tab size of .250 and has a case quantity of 10 bags.

Need Help?

Questions? We can help
[Contact Us](#)



Like One person likes this. [Sign Up](#) to see what your friends like.

- Overview
- Documentation

Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.065 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
China RoHS - Below MCV	Yes
Conductor Sizes	22 - 18 AWG
CSA File Number	LR22190
Diameter (D)	0.3 Inch
EU RoHS Compliant	Yes
Fastener Orientation	Male
Insulation Material	Nylon
Length (L)	0.95 Inch
Mates with Male Tab Width (W')	0.25 Inch
Maximum Insulation Outer Diameter	0.145 Inch
Packaging	25 per bag
Pad Width	0.25 Inch
Terminal Style	Fully Insulated
Terminal Type	Disconnect
Thickness	0.032 Inch
UL File Number	E70512
Width (W)	0.44 Inch

Manufacturing Origin: USA

The designation that a product is Manufactured in the USA means the product undergoes substantial transformation in one of our U.S. Manufacturing plants. Some products contain imported components.

Note: 3M products offered on a government contract that require country of origin representation must be certified by 3M Trade Compliance. Contact customer service at 800-245-3573 to request a certificate.

