



NIC COMPONENTS CORP.


70 Maxess Road • Melville, New York 11747
(631) 396-7500 • Fax (631) 396-7575

6/24/11

INDIVIDUAL SPECIFICATION

NIC P/N: NCB-H0805A601TR200F

Specifications:	
Impedance Value:	600Ω (100MHz, +25°C)
Impedance Tolerance:	± 25%
Operating Temperature Range:	-55°C ~ +125°C
DC Current Rating:	2,000mA (+25°C)
DC Resistance:	0.090Ω max.
Dimensions (mm):	
Length (L):	2.00 +0.3/-0.1
Width (W):	1.25 ± 0.20
Height (H):	0.85 ± 0.20
Termination Width (P):	0.50 ± 0.30

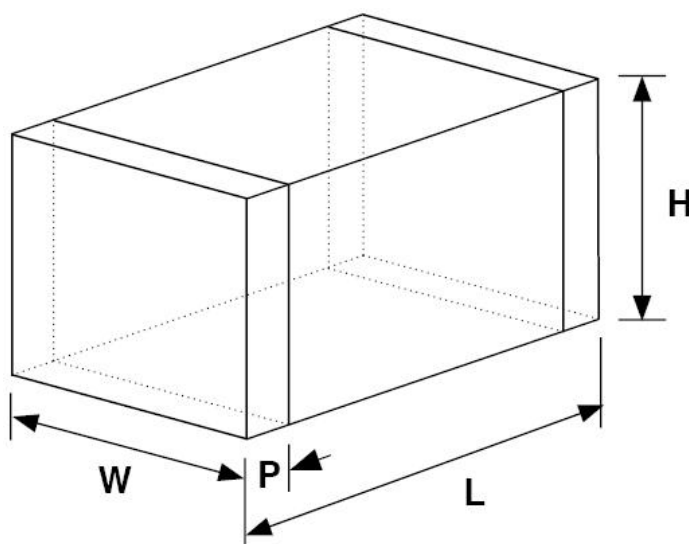

ISO 9001-2000 REGISTERED