

MHDMR-19-02-F-TH-L-TR

MHDMR SERIES

MINI HIGH SPEED I/O RECEPTACLES

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?MHDMR

Insulator Material:

Black Glass Filled
Thermoplastic

Contact Material:

Phosphor Bronze

Shell Material:

Brass

Plating:

Au over Ni on contacts,
Ni on shell

Operating Temp Range:

-25°C to +85°C

Voltage Rating:

40 VAC

Contact Resistance:

30 mΩ

Minimum Cycles:

100

Lead-Free Solderable:


Yes

RoHS Compliant:

Yes

SMT Lead Coplanarity:

(0,10 mm) .004" max


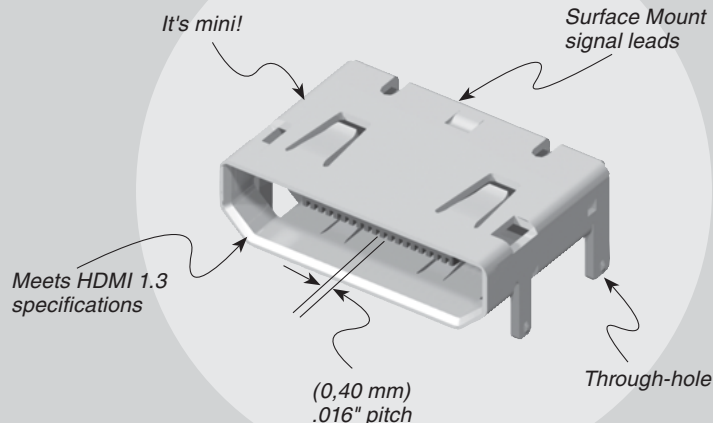


RECOGNITIONS

For complete scope of recognitions see www.samtec.com/quality



MHDMR	19	LEAD STYLE	PLATING	TAIL OPTION	LATCH OPTION	TR
	-02		-F	-TH	-L	-TR
	= Surface Mount		= Gold Flash on contact and tail	= Through-hole	= Latching	= Tape & Reel Packaging
			-H			
			= 30μ" (0,76 μm) Gold on contact, Gold Flash on tails			

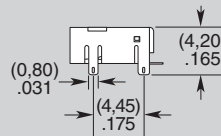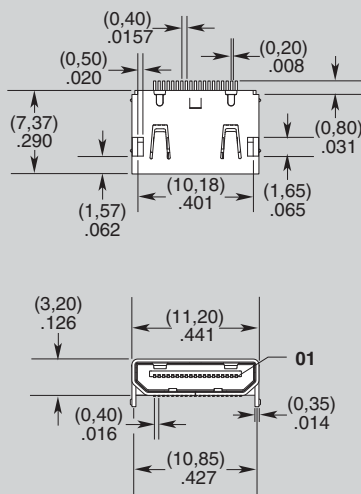

Note: Some lengths, styles and options are non-standard, non-returnable.