 
 





TE Connectivity: Every Connection Counts
© 2015 TE Connectivity Ltd. family of companies. All Rights Reserved

+ CONNECTORS

TERMINALS

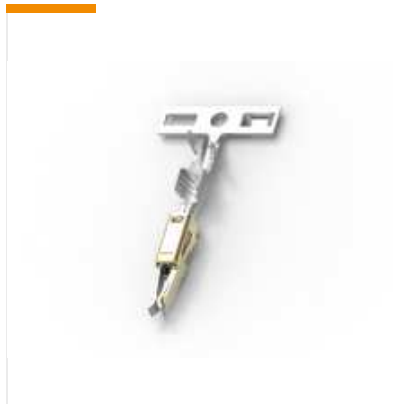

TE CONNECTIVITY (TE)

MT 2, CONTACT

Micro Timer II , Timer Connector System

2141900-2

TE Internal Number: 2141900-2

Always EU RoHS/ELV Compliant

Terminal Style **Receptacle/Socket**

Mating Tab Width (mm) **1.6**

Mating Tab Thickness **.6 mm [.024 in]**

Terminal Transmits **0 – 24 A (Low Power)**

Sealed **No**

✓ Active



PRODUCT DRAWING

English



3D PDF

Product Drawings

[PRODUCT GROUP DRAWING FOR MICRO TIMER 2 CONTACT TYPE A](#)

PDF

English

[MICRO TIMER 2 CONTACT](#)

TIF

German

CAD Files

[3D PDF](#)

PDF

3D

[Customer View Model](#)

2D_DXF.ZIP

English

[Customer View Model](#)

3D_IGS.ZIP

English

[Customer View Model](#)

3D_STP.ZIP

English

Product Specifications

Product Specification

[EG**Micro Timer 2 Kontakt](#)

PDF

English

Application Specification

[EG**Micro Timer 2 Kontakt](#)

TIF

English[Allgemeine Crimpspezifikation / GENERAL CRIMP SPEC.](#)

PDF

German[Micro Timer 2+3 Contact](#)

PDF

English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Sealed

No

Primary Locking Feature

Locking Lance

Wire Type

Copper

Contact Features

Terminal Style

Receptacle/Socket

Mating Tab Width (mm)

1.6


Mating Tab Thickness

.6 mm [.024 in]


	Interface Plating	Tin (Sn)
Termination Features	Termination Method	Crimp
Packaging Features	Packaging Method	Reel
	Packaging Quantity	4500
Other	Terminal Transmits	0 – 24 A (Low Power)
Product Compliance	Statement of Compliance PDF VIEW ALL PRODUCT COMPLIANCE	

Products - 5 Results	View All	Compare 0/10 
-----------------------------	--------------------------	--

Relation Type ▼

 RELATIONSHIP Toolings Tooling	See All Toolings
--	----------------------------------

PRODUCT - TOOLINGS

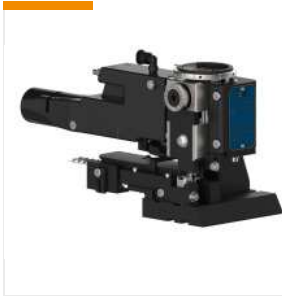

Application Tooling - OCEAN Applicators
AMP

OC-PA-S-FA-062F0900-
001-0223 - 2-2151050-2

TE INTERNAL NUMBER: 2-2151050-2

✓ Active

Not in Scope for EU RoHS/ELV
Compliance

Region **Worldwide**

Tool Type **Applicator**

Spare Parts Tooling **No**

Applicator Style **OCEAN - Pacific**


Applicator Feed Style **Side Feed**

RELATIONSHIP

Toolings
Tooling

[See All Toolings](#)

PRODUCT - TOOLINGS

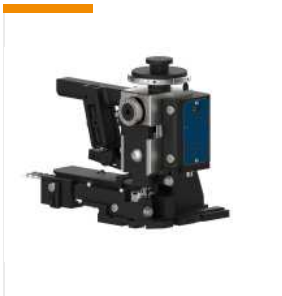

Application Tooling - OCEAN Applicators
AMP

OC-AT-S-FM-062F0900-
001-0223 - 2151050-1

TE INTERNAL NUMBER: 2151050-1

✓ Active

Not in Scope for EU RoHS/ELV
Compliance

Region **Worldwide**

Tool Type **Applicator**

Spare Parts Tooling **No**

Applicator Style **OCEAN - Atlantic**

Applicator Feed Style **Side Feed**

RELATIONSHIP

Toolings
Tooling[See All Toolings](#)

PRODUCT - TOOLINGS



Application Tooling - OCEAN Applicators
AMP

OC-PA-S-FM-062F0900-
001-0223 - 2-2151050-1

TE INTERNAL NUMBER: 2-2151050-1

✓ Active

Not in Scope for EU RoHS/ELV
Compliance

Region **Worldwide**

Tool Type **Applicator**

Spare Parts Tooling **No**

Applicator Style **OCEAN - Pacific**

Applicator Feed Style **Side Feed**