

LUMOTAST 75 IP40, signal lamps, square collar, flat bezel, Solder terminal

DISCONTINUED



Description

The LUMOTAST 75 IP 40 signal lamps have proven themselves over decades. The well-known connection and labeling concept make the LUMOTAST 75 IP 40 series your reliable component. These signal lamps offer protection class IP 40 according to DIN.

technical data

> general

|                                                             |         |
|-------------------------------------------------------------|---------|
| Collar color                                                | black   |
| Collar shape                                                | square  |
| Operating temperature, min.                                 | -25 °C  |
| Operating temperature, max.                                 | 55 °C   |
| Storage temperature, min.                                   | -40 °C  |
| Storage temperature, max.                                   | 80 °C   |
| illuminated                                                 | Yes     |
| Lamp socket                                                 | T4.5    |
| Packaging                                                   | Box     |
| Packaging unit                                              | 10 pcs. |
| Net weight                                                  | 7.5 g   |
| Degree of protection, front side, according to DIN EN 60529 | IP40    |
| Minimum order quantity (MOQ)                                | 10 pcs. |
| RoHS compliant                                              | Yes     |
| REACH compliant                                             | Yes     |
| Country of origin                                           | HU      |

direct links

> RAFI eCatalog

> mounting diameters


|                          |         |
|--------------------------|---------|
| Outside dimension, width | 18 mm   |
| Mounting hole            | 16.2 mm |
| Mounting depth           | 33.5 mm |
| Installation height      | 7.5 mm  |

> mechanical data

|                      |                 |
|----------------------|-----------------|
| Terminal on the rear | Solder terminal |
| Fixing               | Threaded ring   |
| Solderability        | Yes             |

## drawings

### Dimensioned drawing

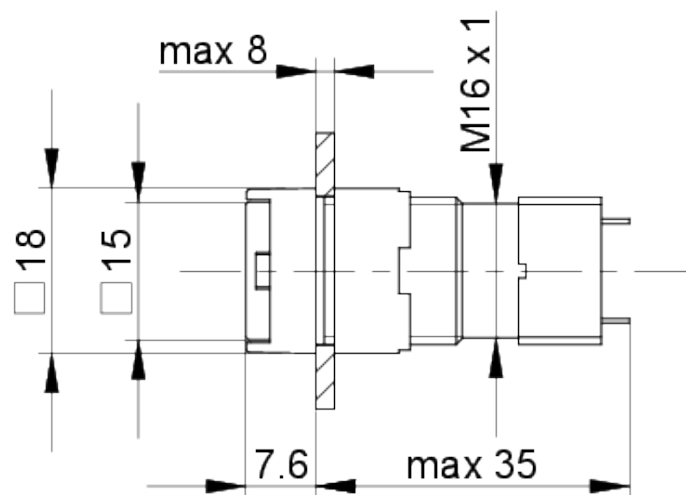

### Mounting hole drawing

