



[Home](#)
[Products](#)
[Online Catalog](#)
[Request Quote](#)
[Order Online](#)
[Check Stock](#)
[Request Print Catalog](#)
[Request Samples](#)
[Engineering Data](#)
[Distributors](#)
[Capabilities Brochure](#)

CALL NOW:
203 888-2133


[Home > 1/4 Hex Male-Female Standoffs](#)

1/4 HEX MALE-FEMALE STANDOFFS

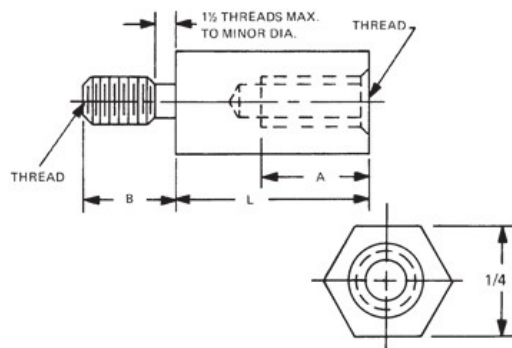

Qty1 *

Qty2

Qty3

	Code	Length
☐	4550	1-1/2
☐	4551	1-9/16
☐	4552	1-5/8
☐	4553	1-11/16
☐	4554	1-3/4
☐	4555	1-13/16
☐	4556	1-7/8
☒	4557	1-15/16
☐	4558	2"
☐	4559	2-1/8
☐	4560	2-1/4
☐	4561	2-3/8
☐	4562	2-1/2

Thread *

Select	Code	Thread
☐	256	2-56
☐	440	4-40
☒	632	6-32
☐	832	8-32

Material *

Select	Code	Material	RoHS
☐	AL	Aluminum	YES
☐	B	Brass	YES
☒	SS	Stainless Steel	YES
☐	S	Steel	YES
☐	N	Nylon	YES

Finish *

☒	Plain Finish
☐	1-Cad clear chromate/commercial*
☐	2-Cad clear chromate*
☐	3-Cad yellow chromate*
☐	4-Chrome over nickel
☐	5-Nickel

[Home](#) [Previous](#) [Next](#)
[Related Metric](#)

Ordering Code

xxxxx	xxx	xx	x
Length	Thread	Material	Finish

PART: 4557 632 SSRed ?'s show missing selections. [Help](#)
[Material Specifications](#)
[Ordering non-standard items](#)
[Request a Drawing](#)
[Add to Cart](#)

Thread Length Code

Thread	A	B
2-56	3/16	5/32
4-40	1/4	3/16
6-32	3/8	1/4
8-32	7/16	3/8

☐	6-Gold iridite*
☐	7-Clear iridite
☐	9-Alodine 1200*
☒	10-Bright chrome
☐	11-Satin chrome
☐	12-Zinc