


OA109AP-IP55



AC Fan - 115V,230V
120 x 38mm (4.7"x1.5")

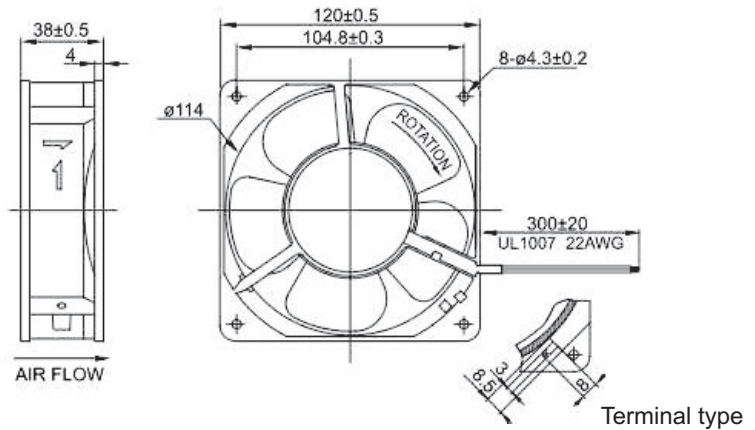

Frame	Diecast Aluminum	Operating Temperature -20C ~ +70C	
Impeller	PBT, UL94V-O plastic	Life Expectancy >40,000 hours (L10, 40C)	
Connection	Terminals	Rated IP55	
Motor	AC shaded pole, impedance	Class B Insulation	
Bearing System	Dual ball	Weight: ~ 1.05 lbs.	
Insulation Resistance	>100M ohm between lead-wire and frame		
Dielectric Strength	1 min at 1500 VAC, 50/60Hz	m2	

Model Number	OA109AP-11-1TBIP55	OA109AP-22-1TBIP55
Part Number	210315302	210615302
Nominal Voltage	115 VAC	230 VAC
Nominal Current	0.16A	.08A
Rated Power	12 W (60Hz)	15 W (60Hz)
Rated Speed (RPM)	3100	3100
Airflow (CFM)	106	106
Noise Level (dB)	46	46
Max. Static Pressure	0.32" H ₂ O	0.32" H ₂ O